



# Better. Where It Counts.

Cummins 2013 Engines For RV Applications.

ISX15 Up To 600 hp.


ISX12 Up To 500 hp.



■ Cummins  
Aftertreatment System

■ Single High-Capacity  
Electronic Control  
Module (ECM)

■ XPI Fuel System

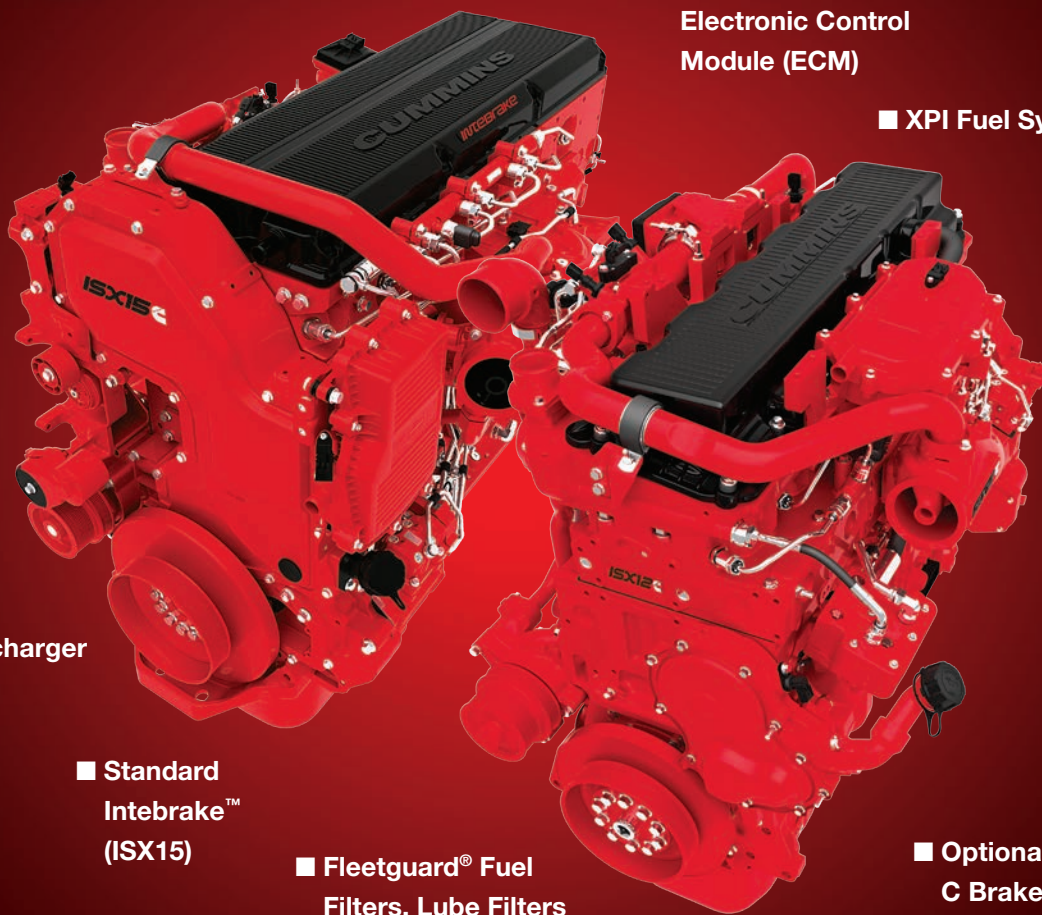


■ VGT™  
Turbocharger

■ Standard  
Intebrate™  
(ISX15)

■ Fleetguard® Fuel  
Filters, Lube Filters  
And Diesel Exhaust  
Fluid (DEF)

■ Optional  
C Brake™  
By Jacobs®  
(ISX12)

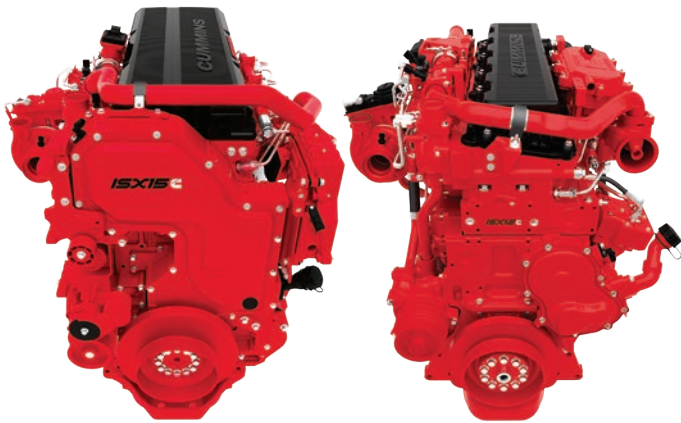

# Better Where It Counts. Cummins ISX15 And ISX12.

Cummins ISX15 and ISX12 are the diesel engines preferred for the largest, most luxurious RVs. Designed and developed as a totally integrated system, the ISX15 and ISX12 deliver:

- Up to 2 percent better fuel economy over previous models through optimization of the turbocharger and control system.
- Strong acceleration and towing capacity at every rpm with Cummins XPI fuel system.
- Smooth, quiet operation with multiple injection events every combustion cycle.
- Near-zero emissions with the proven Cummins Aftertreatment System, and On-Board Diagnostics to monitor and ensure clean operation.
- 5-year/100,000-mile (160,934 km) base warranty.

## Better Customer Support. Every Hour.

Cummins has the largest and most capable parts and service network in North America. Our 3,500 certified service locations with qualified technicians and Genuine Cummins Parts ensure fast and accurate repairs. Call Cummins Care at 1-800-CUMMINS™ (1-800-286-6467), and you'll get 24/7/365 service location assistance from a Cummins Care representative.

Also, enjoy comfortable guest lounges, Internet access and complimentary overnight parking with electrical hookups at one of over 40 Coach Care™ facilities located near America's most popular RV destinations. Check out the Coach Care section at [funroads.com](http://funroads.com).

## ISX15 and ISX12 Ratings

Engine Model	Advertised HP (LW)	Peak Torque LB-FT (N•M) @ RPM
ISX15 600	600 (447)	1950 (2644) @ 1200
ISX15 550	550 (410)	1850 (2508) @ 1200
ISX12 500	500 (373)	1645 (2230) @ 1200
ISX12 450	450 (336)	1550 (2102) @ 1200

## ISX15 Specifications

Clutch Engagement Torque	1,000 lb-ft	1,356 N•m
Number of Cylinders	6	
Biodiesel Compatibility	Up to B20	
System Weight (Dry)	3,204 lb	1,453 kg

## ISX12 Specifications

Clutch Engagement Torque	800 lb-ft	1085 N•m
Number of Cylinders	6	
Biodiesel Compatibility	Up to B20	
System Weight (Dry)	2,880 lb	1,306 kg

## ISX15 and ISX12 Maintenance Intervals

Maintenance Item	ISX15	ISX12	Months
	Miles/Kilometers	Miles/Kilometers	
Oil and Filter	30,000 mi	25,000 mi	6 (ISX15) 6 (ISX12)
	48,000 km	40,000 km	
Fuel Filter	30,000 mi	30,000 mi	6 (ISX15) 6 (ISX12)
	48,000 km	48,000 km	
Coolant Filter	50,000 mi	50,000 mi	12 (ISX15) 12 (ISX12)
	80,000 km	80,000 km	
Valve Adjustment	500,000 mi	250,000 mi	60 (ISX15) 24 (ISX12)
	800,000 km	400,000 km	
Coalescing Filter	125,000 mi	150,000 mi	
	200,000 km	240,000 km	
DEF Filter	300,000 mi	300,000 mi	
	480,000 km	480,000 km	
Diesel Particulate Filter	200,000 mi	200,000 mi	
	320,000 km	320,000 km	

Consult QuickServe® Online ([quickserve.cummins.com](http://quickserve.cummins.com)) or your Owners Manual for the most accurate and up-to-date information.



Cummins Inc.  
Box 3005  
Columbus, IN 47202-3005  
U.S.A.

Phone: 1-800-CUMMINS™ (1-800-286-6467)  
Internet: [cumminsengines.com](http://cumminsengines.com)

[Twitter.com/CumminsEngines](https://twitter.com/CumminsEngines)  
[YouTube.com/CumminsEngines](https://www.youtube.com/CumminsEngines)

Bulletin 4971465 Printed in U.S.A. Rev. 8/17  
©2017 Cummins Inc.