


Before 2010

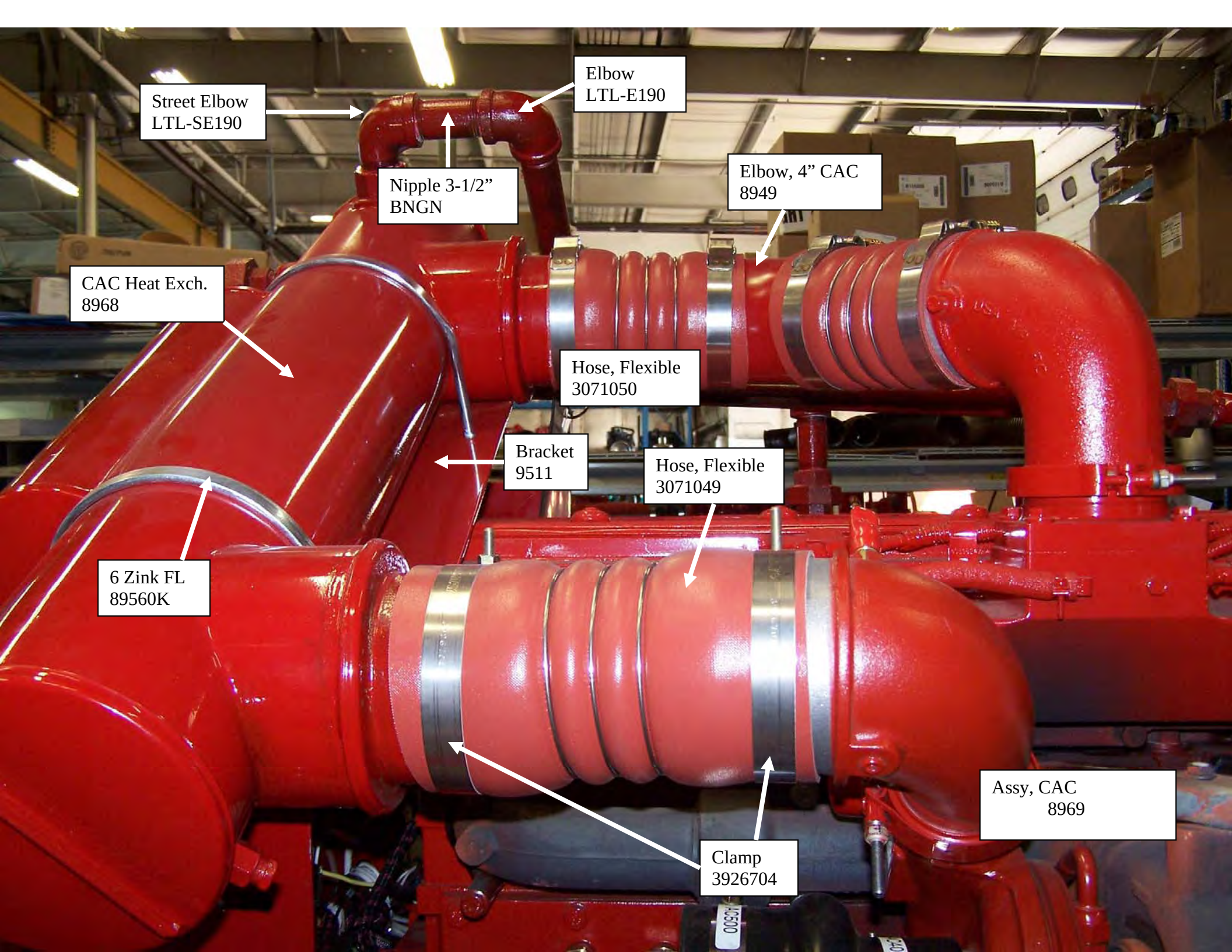

Street Elbow
LTL-SE190

Elbow
LTL-E190

Nipple 3-1/2"
BNGN

Elbow, 4" CAC
8949

CAC Heat Exch.
8968

Hose, Flexible
3071050


Bracket
9511

Hose, Flexible
3071049

6 Zink FL
89560K

Clamp
3926704

Assy, CAC
8969

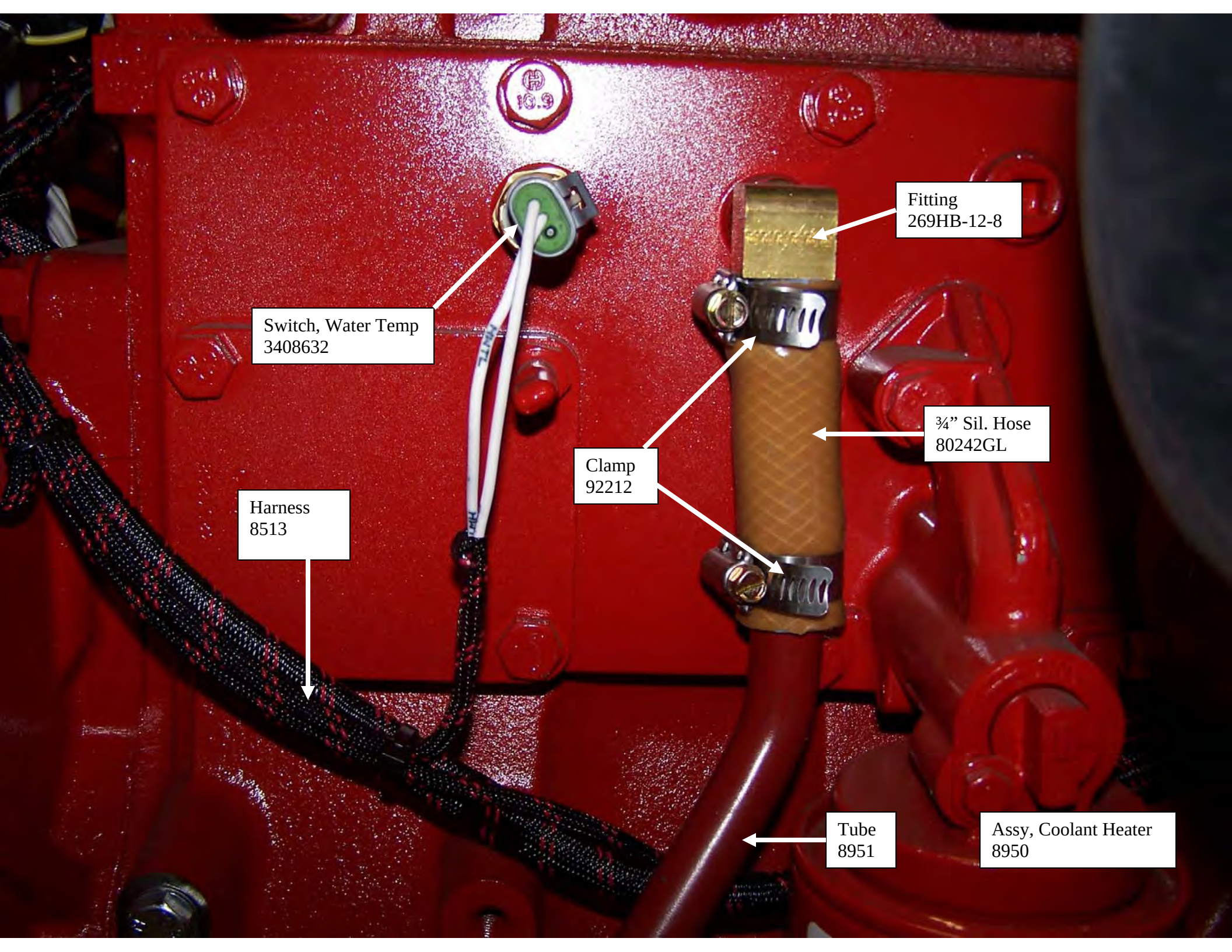

Switch, Water Temp
3408632

Harness
8513


Clamp
92212

Fitting
269HB-12-8

3/4" Sil. Hose
80242GL

Tube
8951

Assy, Coolant Heater
8950

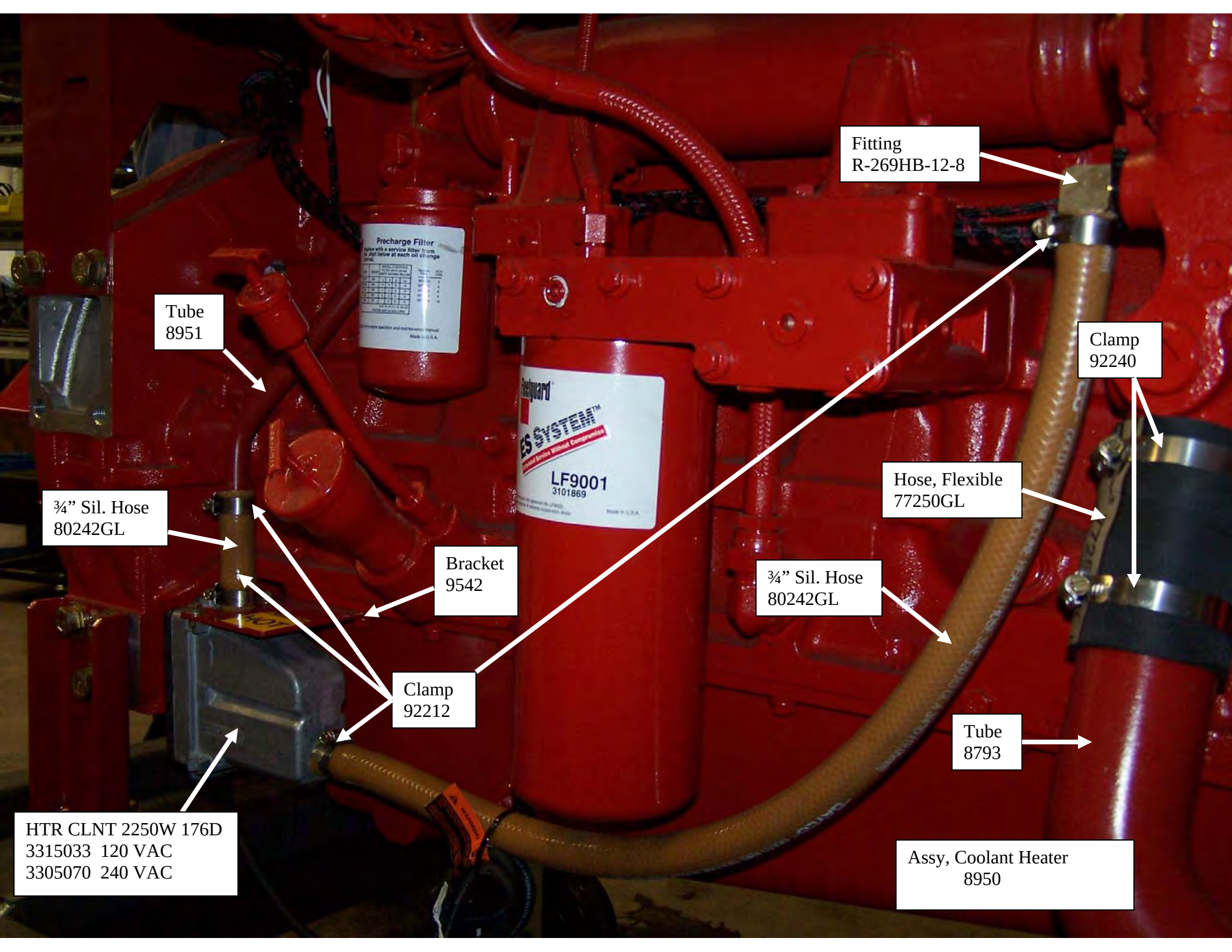

Tube
8951

¾" Sil. Hose
80242GL

Bracket
9542

Clamp
92212

Fitting
R-269HB-12-8

Clamp
92240


Hose, Flexible
77250GL

¾" Sil. Hose
80242GL

Tube
8793

HTR CLNT 2250W 176D
3315033 120 VAC
3305070 240 VAC

Assy, Coolant Heater
8950

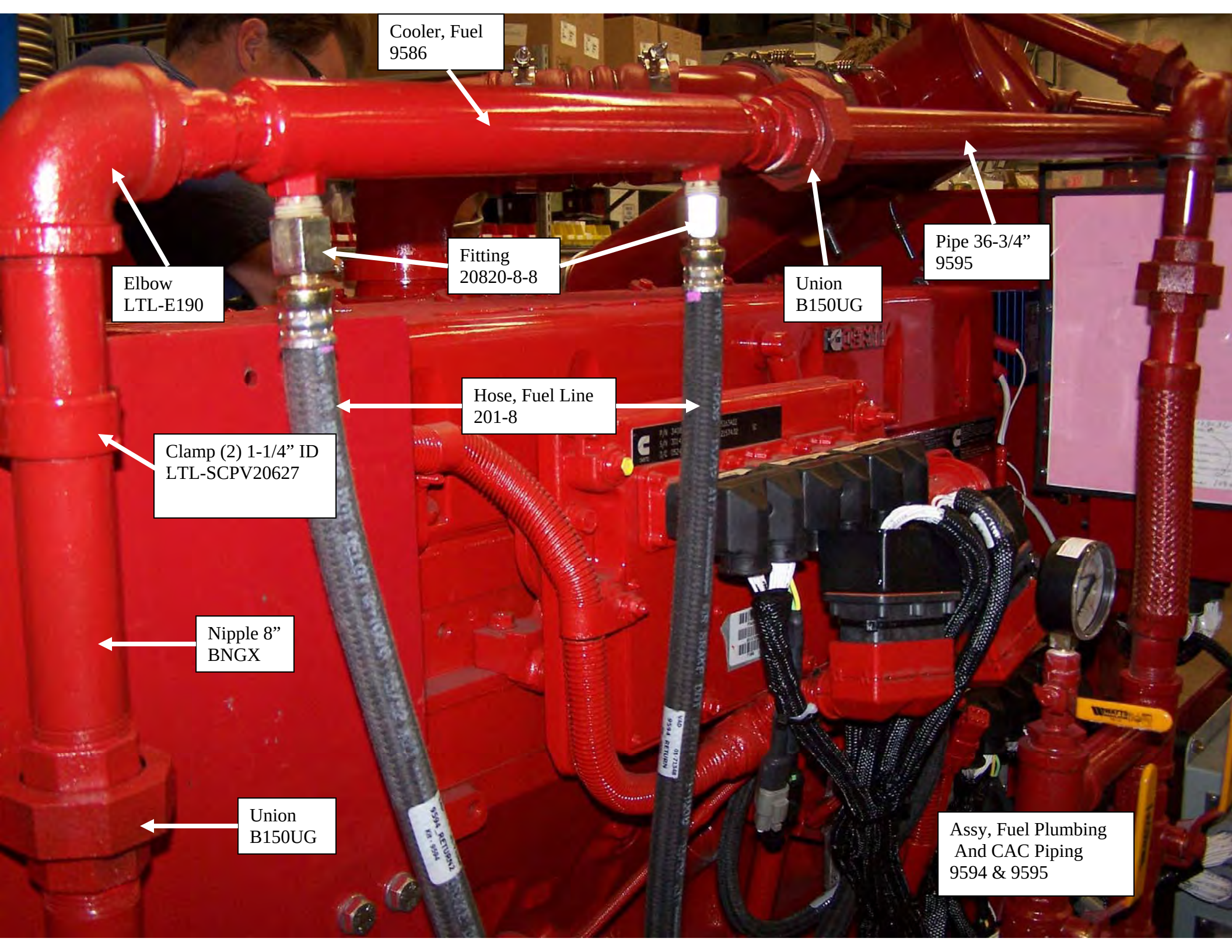

Cooler, Fuel
9586

Elbow
LTL-E190

Fitting
20820-8-8

Union
B150UG

Pipe 36-3/4"
9595


Hose, Fuel Line
201-8

Clamp (2) 1-1/4" ID
LTL-SCPV20627

Nipple 8"
BNGX

Union
B150UG

Assy, Fuel Plumbing
And CAC Piping
9594 & 9595

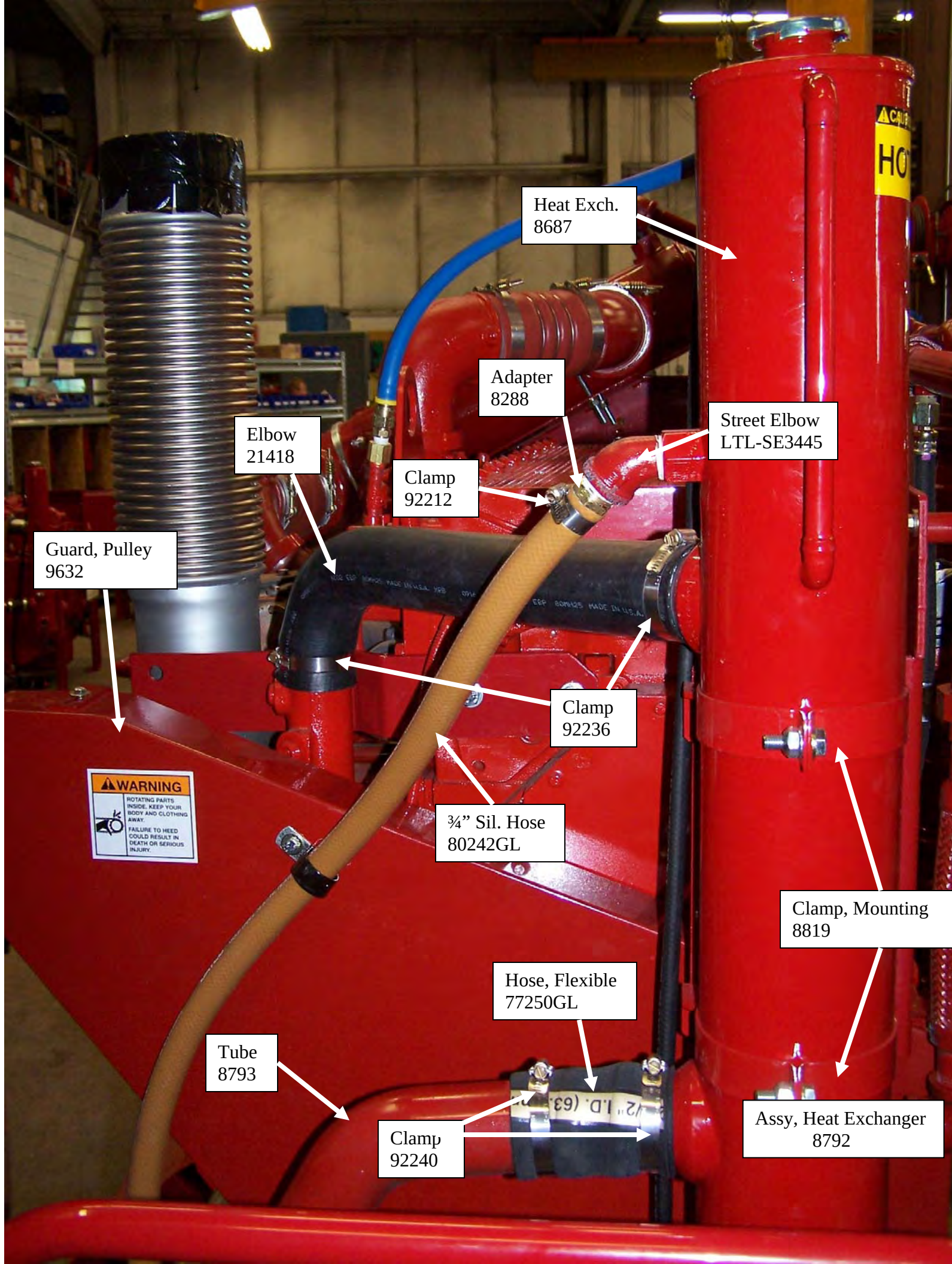

Heat Exch.
8687

Adapter
8288

Street Elbow
LTL-SE3445

Elbow
21418

Clamp
92212

Guard, Pulley
9632

Clamp
92236

3/4" Sil. Hose
80242GL

Clamp, Mounting
8819


Hose, Flexible
77250GL

Tube
8793

Clamp
92240

Assy, Heat Exchanger
8792

WARNING
ROTATING PARTS
INSIDE. KEEP YOUR
BODY AND CLOTHING
AWAY.
FAILURE TO HEED
COULD RESULT IN
DEATH OR SERIOUS
INJURY.

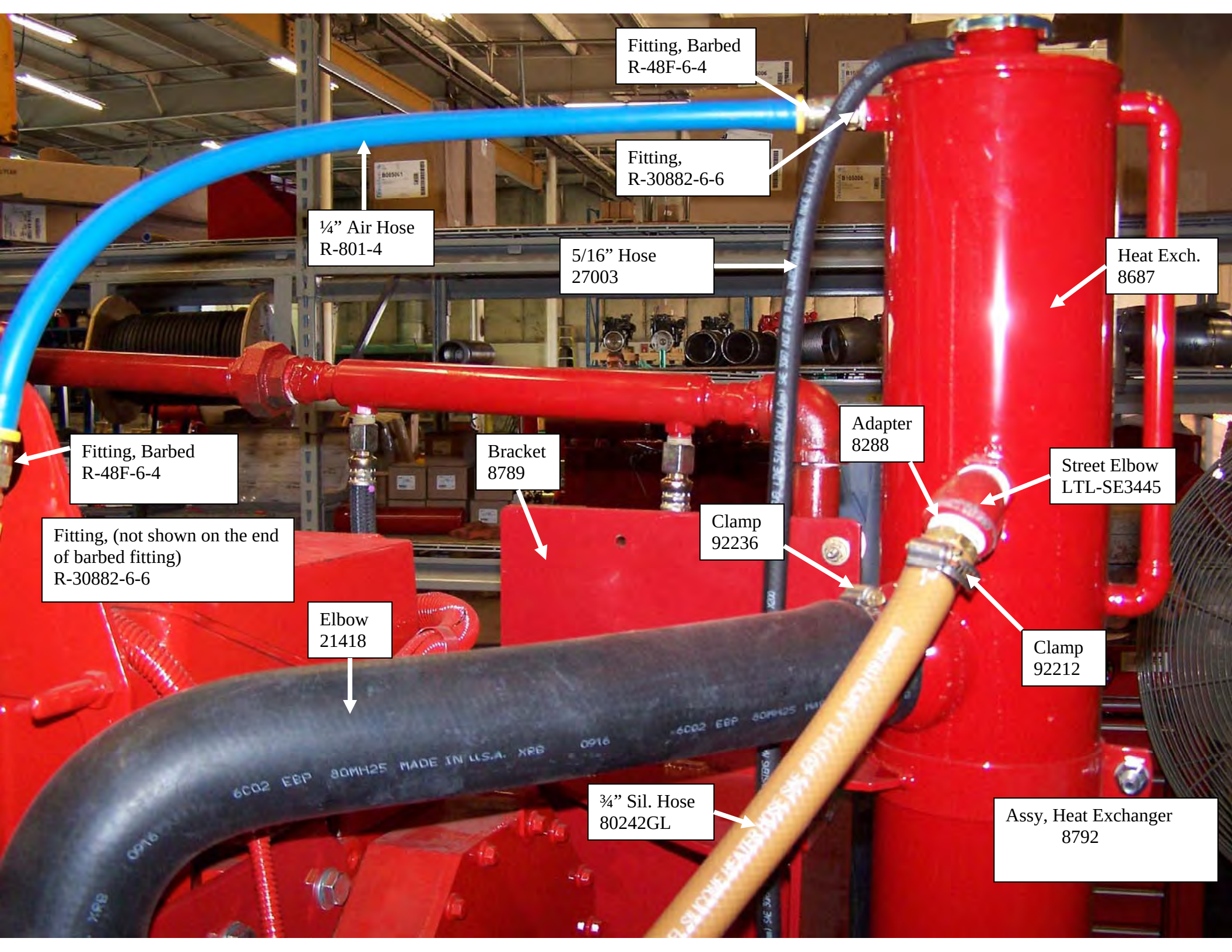

Fitting, Barbed
R-48F-6-4

Fitting,
R-30882-6-6

1/4" Air Hose
R-801-4

5/16" Hose
27003

Heat Exch.
8687

Fitting, Barbed
R-48F-6-4

Fitting, (not shown on the end
of barbed fitting)
R-30882-6-6

Bracket
8789

Adapter
8288

Street Elbow
LTL-SE3445


Clamp
92236

Clamp
92212

Elbow
21418

3/4" Sil. Hose
80242GL

Assy, Heat Exchanger
8792

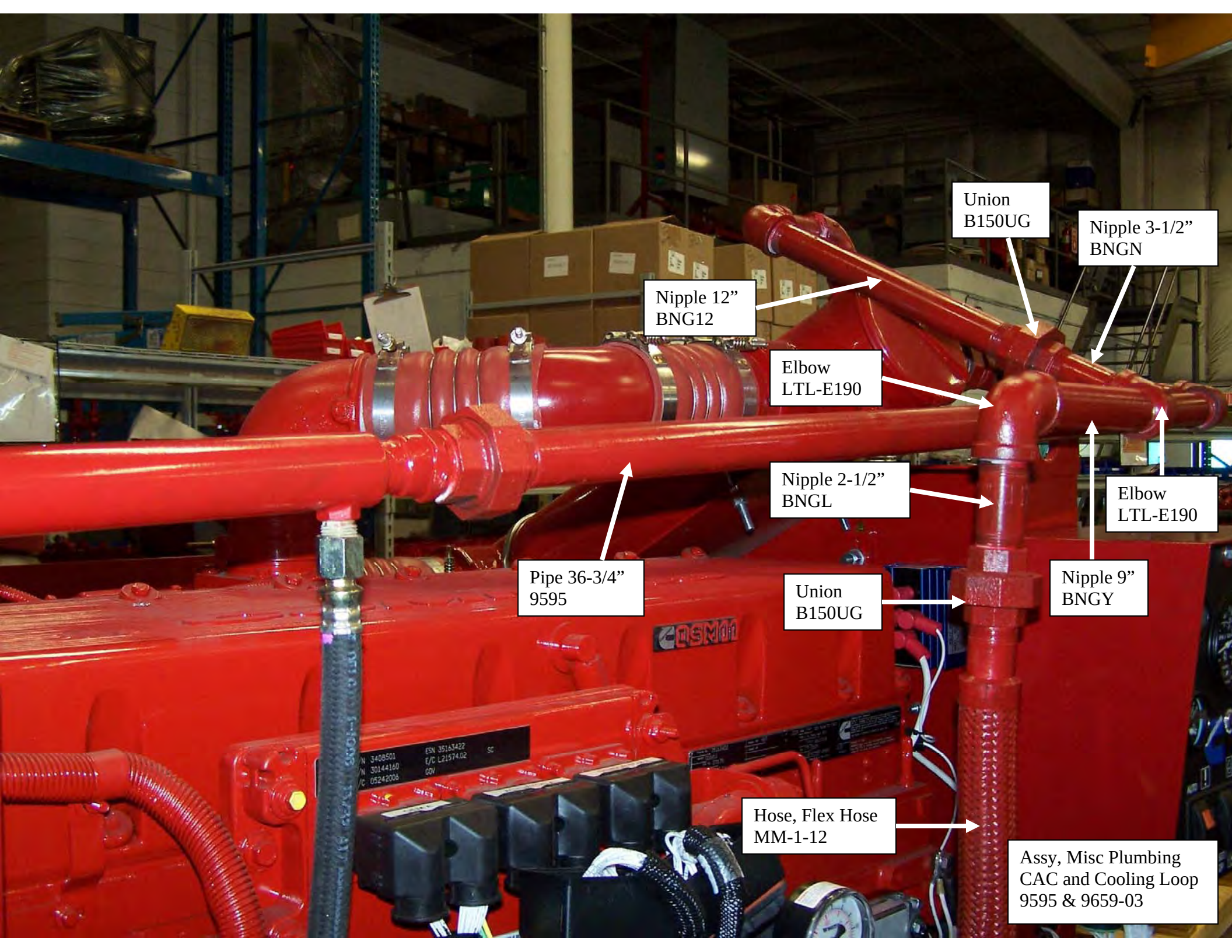

Nipple 12"
BNG12

Elbow
LTL-E190

Union
B150UG

Nipple 3-1/2"
BNGN

Nipple 2-1/2"
BNGL

Elbow
LTL-E190


Pipe 36-3/4"
9595


Union
B150UG

Nipple 9"
BNGY

Hose, Flex Hose
MM-1-12

Assy, Misc Plumbing
CAC and Cooling Loop
9595 & 9659-03

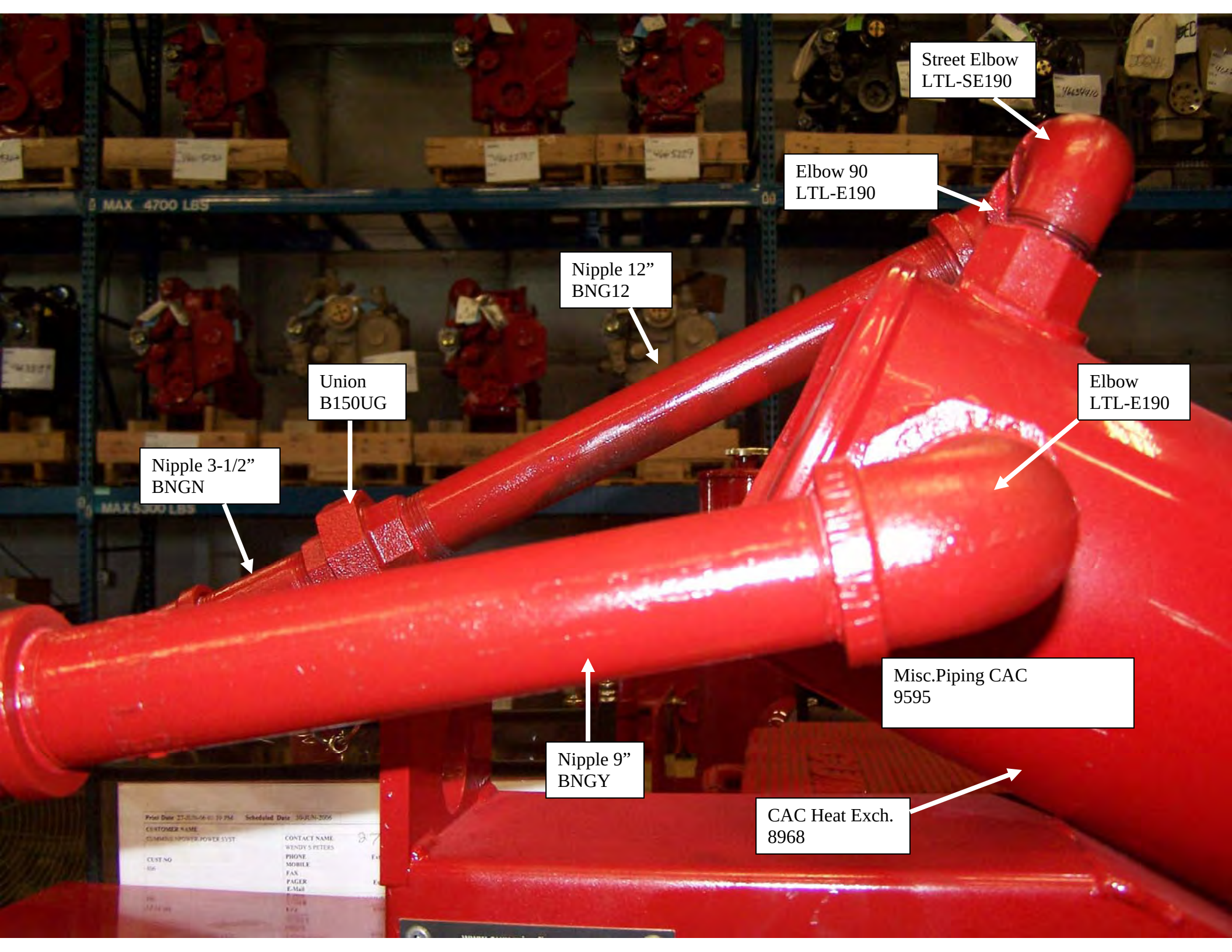

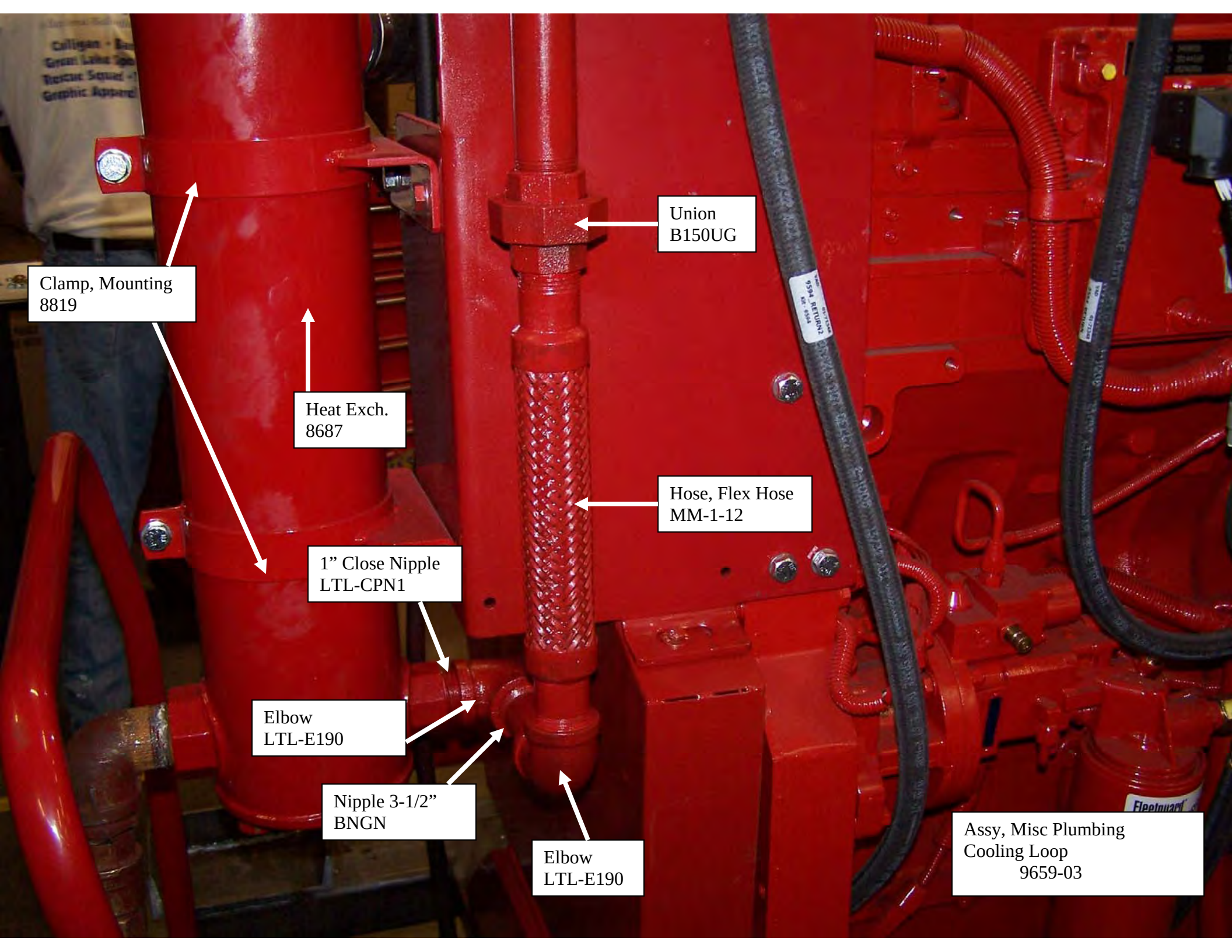

Clamp, Mounting
8819

Heat Exch.
8687

Union
B150UG

Hose, Flex Hose
MM-1-12


1" Close Nipple
LTL-CPN1

Elbow
LTL-E190

Nipple 3-1/2"
BNGN

Elbow
LTL-E190

Assy, Misc Plumbing
Cooling Loop
9659-03

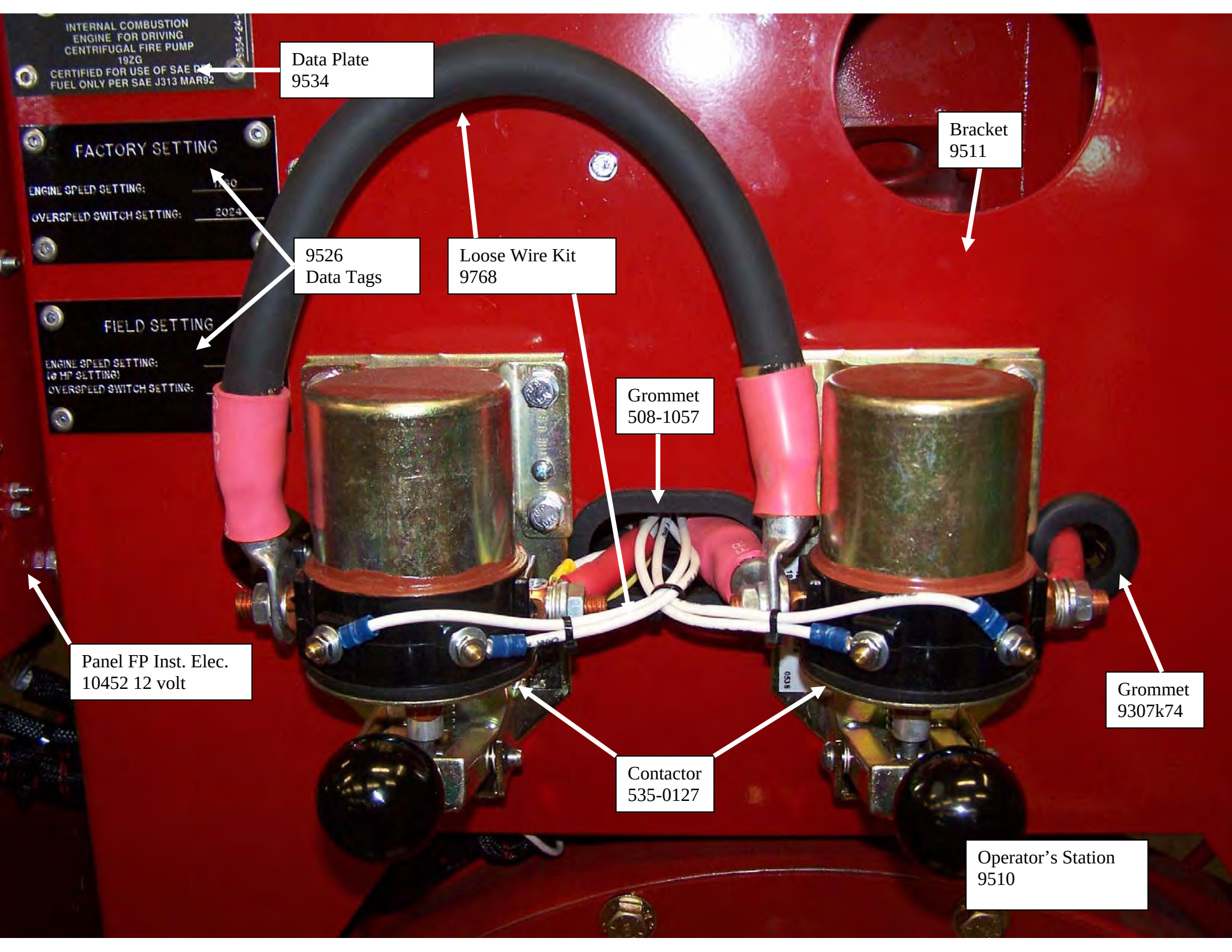

INTERNAL COMBUSTION
ENGINE FOR DRIVING
CENTRIFUGAL FIRE PUMP
192G
CERTIFIED FOR USE OF SAE D
FUEL ONLY PER SAE J313 MAR92

Data Plate
9534

FACTORY SETTING
ENGINE SPEED SETTING: 1800
OVERSPEED SWITCH SETTING: 2024

9526
Data Tags

Loose Wire Kit
9768

Bracket
9511

FIELD SETTING
ENGINE SPEED SETTING:
(@ HP SETTING)
OVERSPEED SWITCH SETTING:

Grommet
508-1057

Panel FP Inst. Elec.
10452 12 volt

Grommet
9307k74

Contactor
535-0127

Operator's Station
9510


Wiring Harness
8513


Isolator, Vibration
51156PS

Bracket
9597

Wiring Harness
9533

ECM Secondary
9596 2 of 2

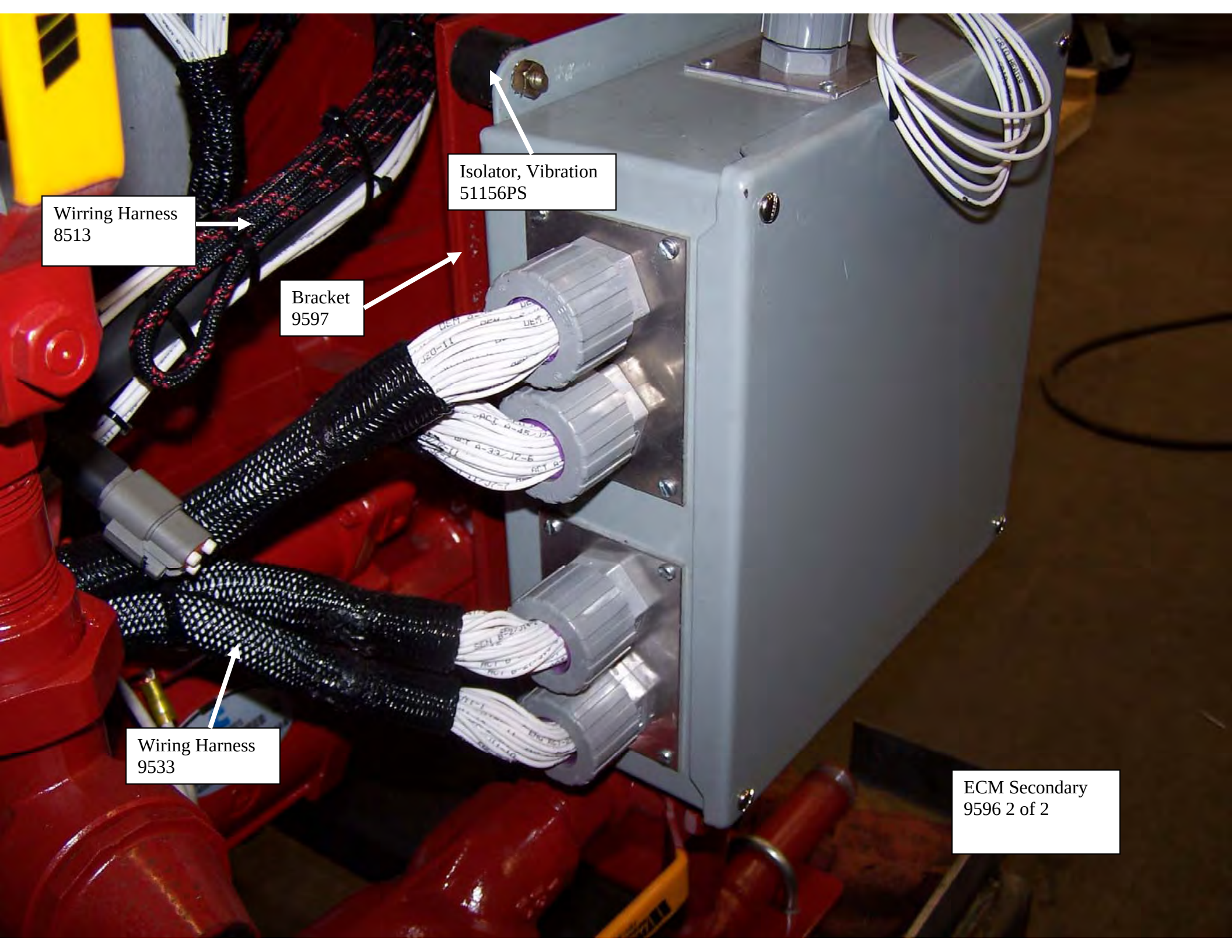

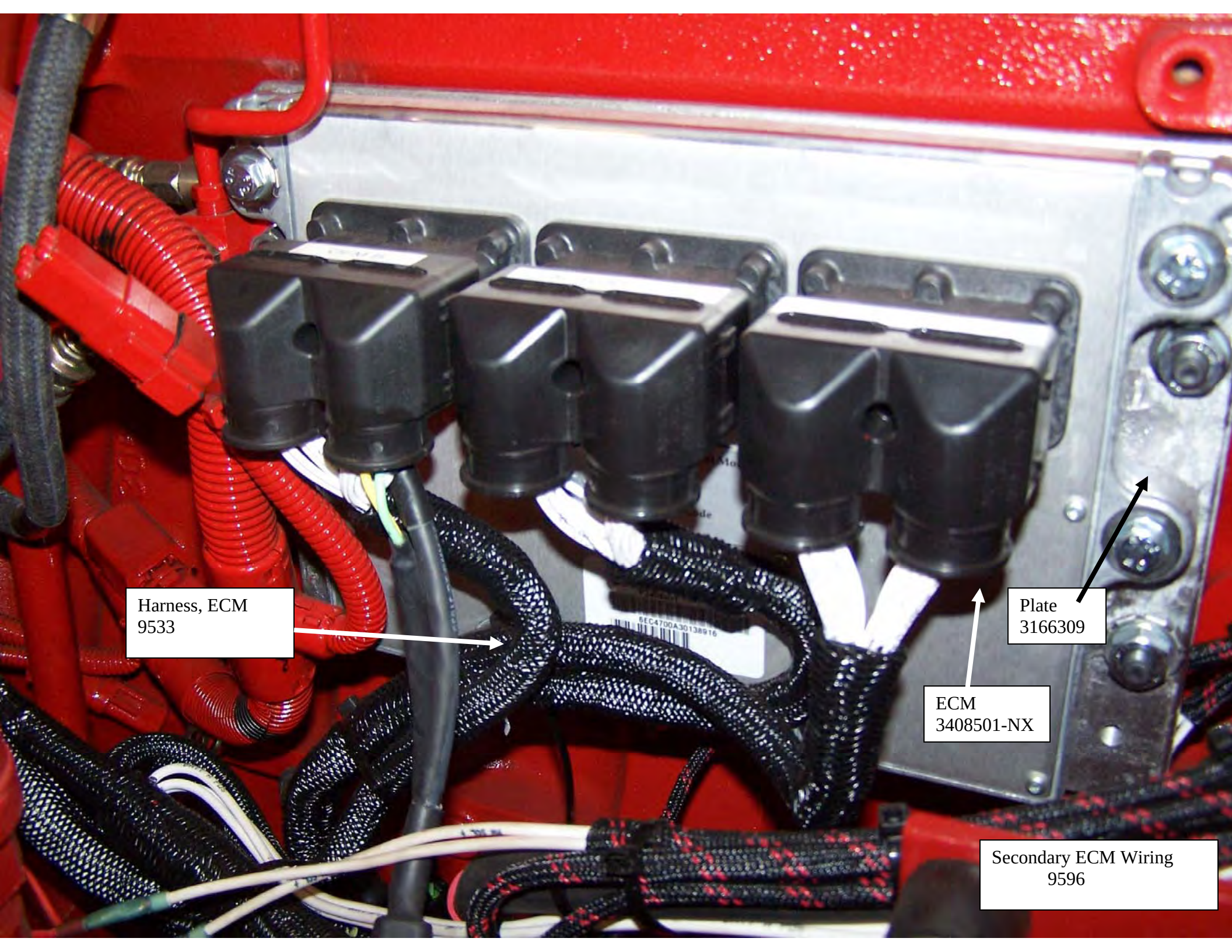


A close-up photograph of an engine's electrical system. The image shows a red-painted metal engine block with a silver-colored metal plate mounted on it. Three black plastic electrical connectors are plugged into the plate. Various wires are visible, including red braided cables, black braided cables, and a bundle of white and yellow wires. A white label with a barcode is attached to one of the black cables. Arrows from text labels point to specific components: the ECM harness, the ECM unit, the mounting plate, and the secondary wiring.

Harness, ECM
9533

ECM
3408501-NX

Plate
3166309

Secondary ECM Wiring
9596

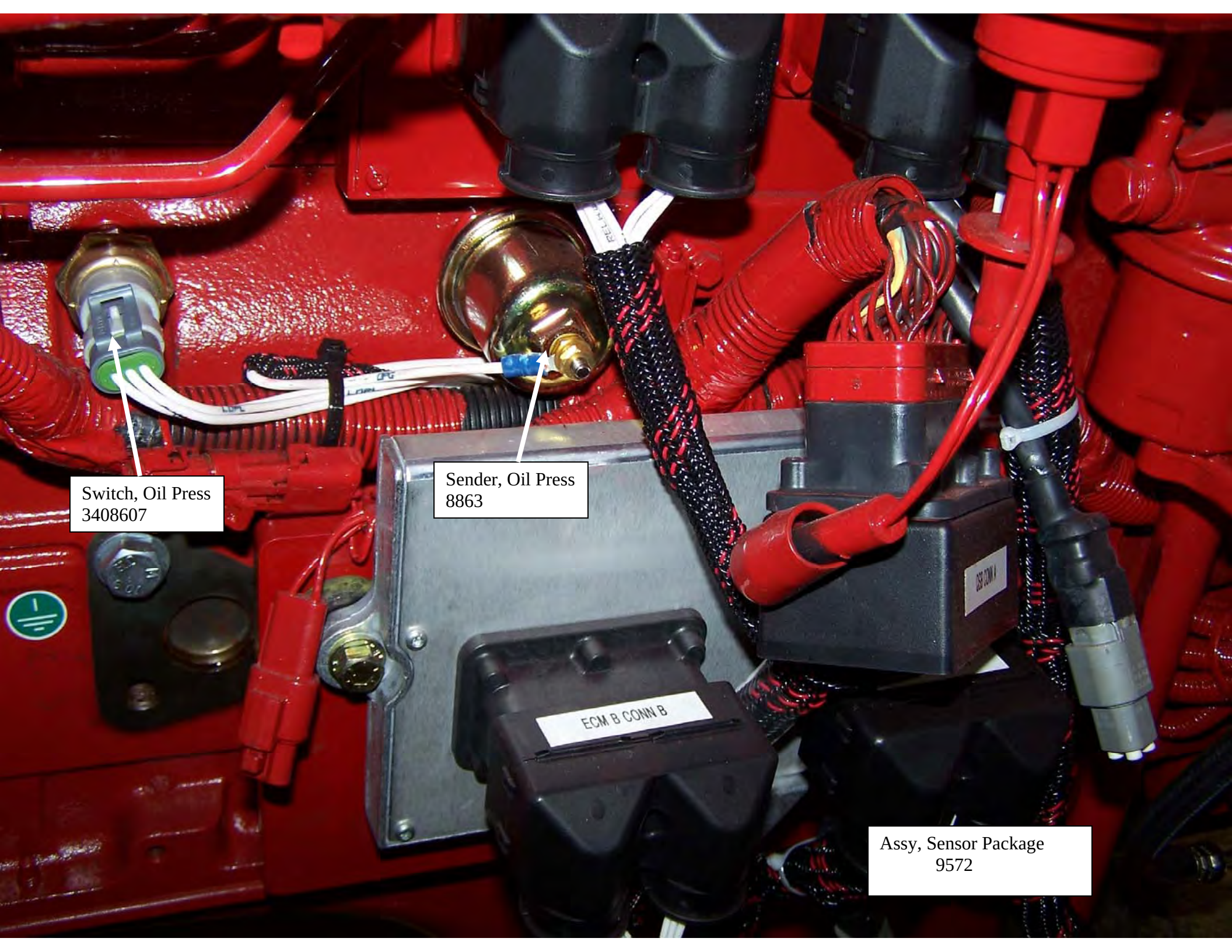

Switch, Oil Press
3408607

Sender, Oil Press
8863

Assy, Sensor Package
9572


Bulkhead
8-WGTX-WLNS

Fuel Line Ext and plug
10233
LTL- SCSP12 (not
shown)


Bulkhead
10-WGTX-WLNS

Fuel Line Ext and plug
10234
LTL- SCSP38 (not
shown)

Assy, Fuel Plumbing
9594

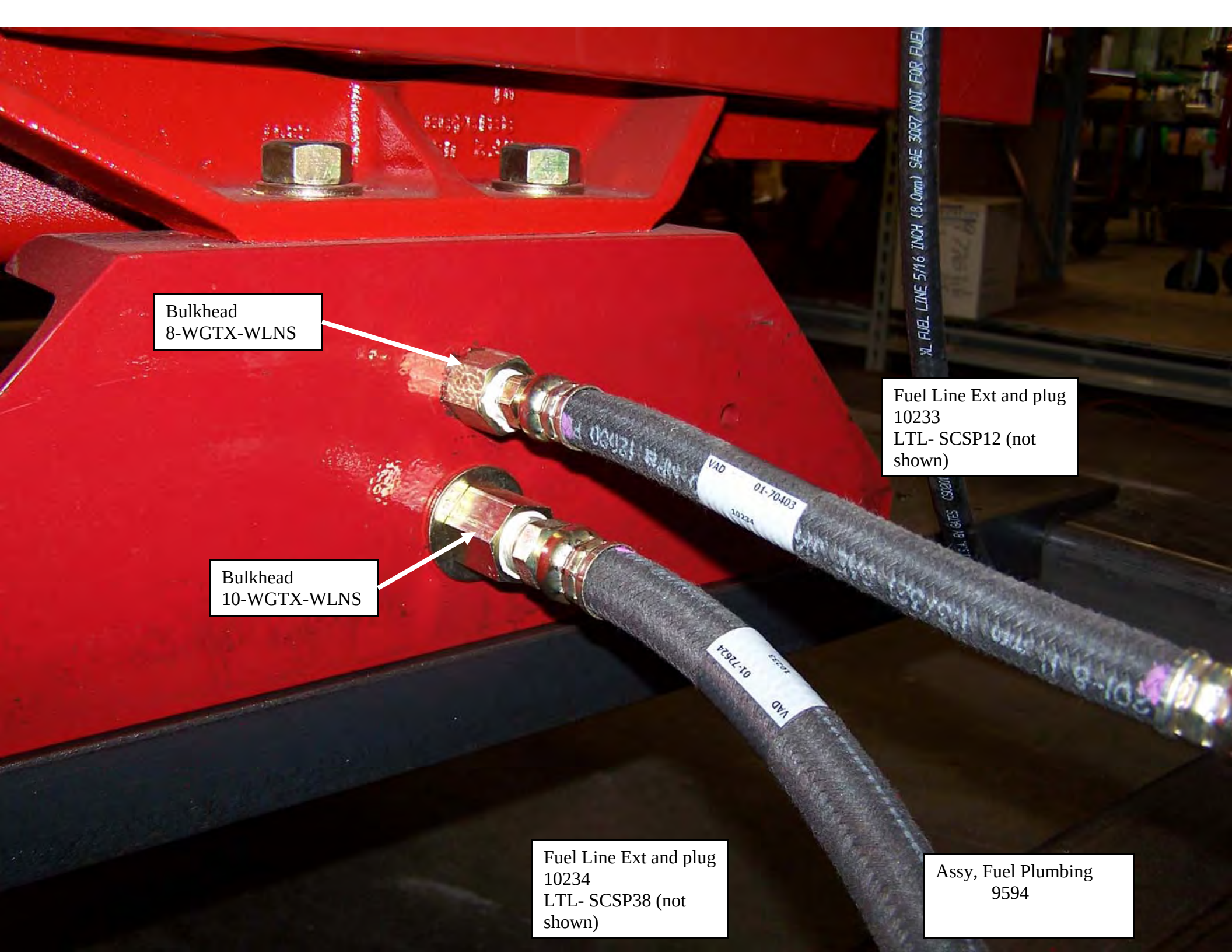

After 2010

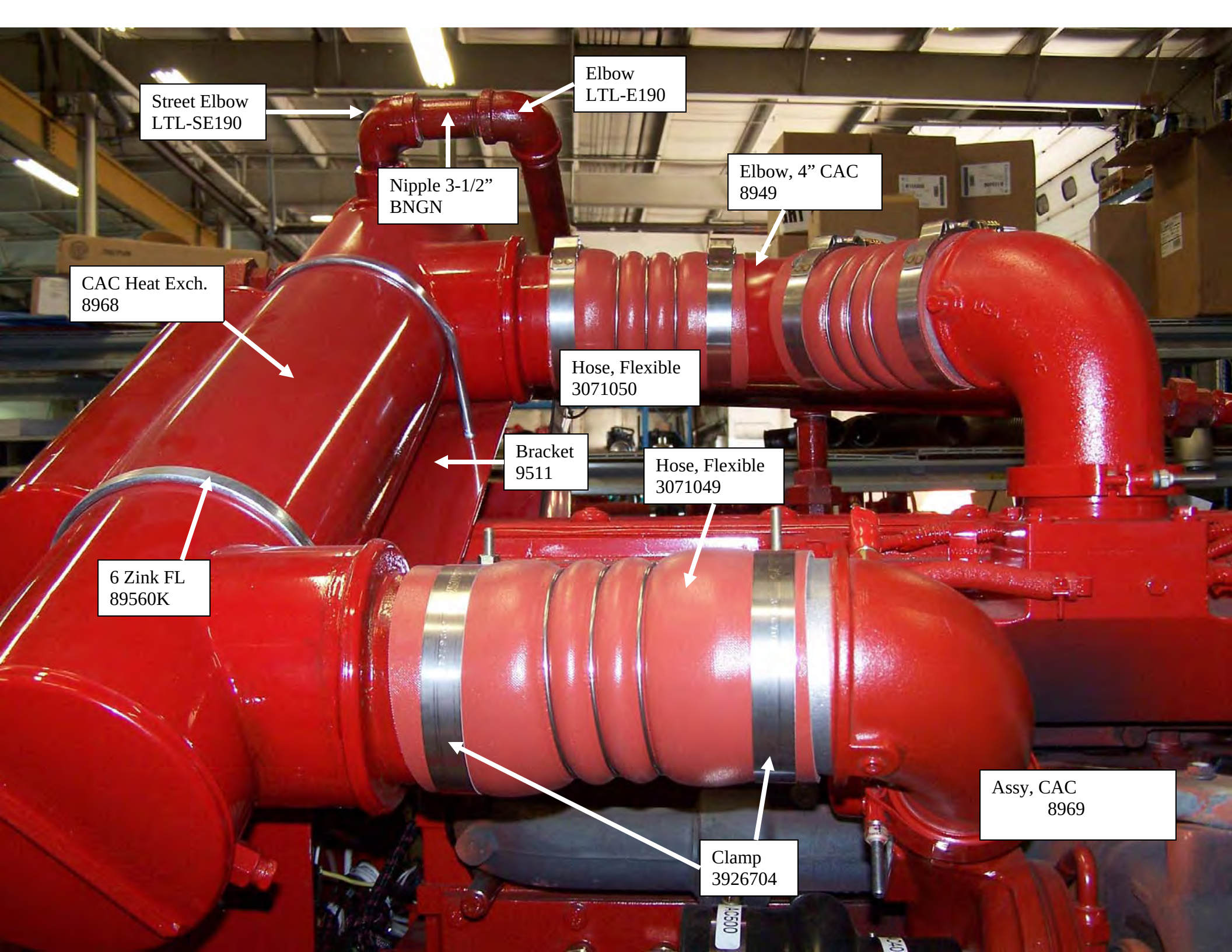

Street Elbow
LTL-SE190

Elbow
LTL-E190

Nipple 3-1/2"
BNGN

Elbow, 4" CAC
8949

CAC Heat Exch.
8968

Hose, Flexible
3071050


Bracket
9511

Hose, Flexible
3071049

6 Zink FL
89560K

Clamp
3926704

Assy, CAC
8969

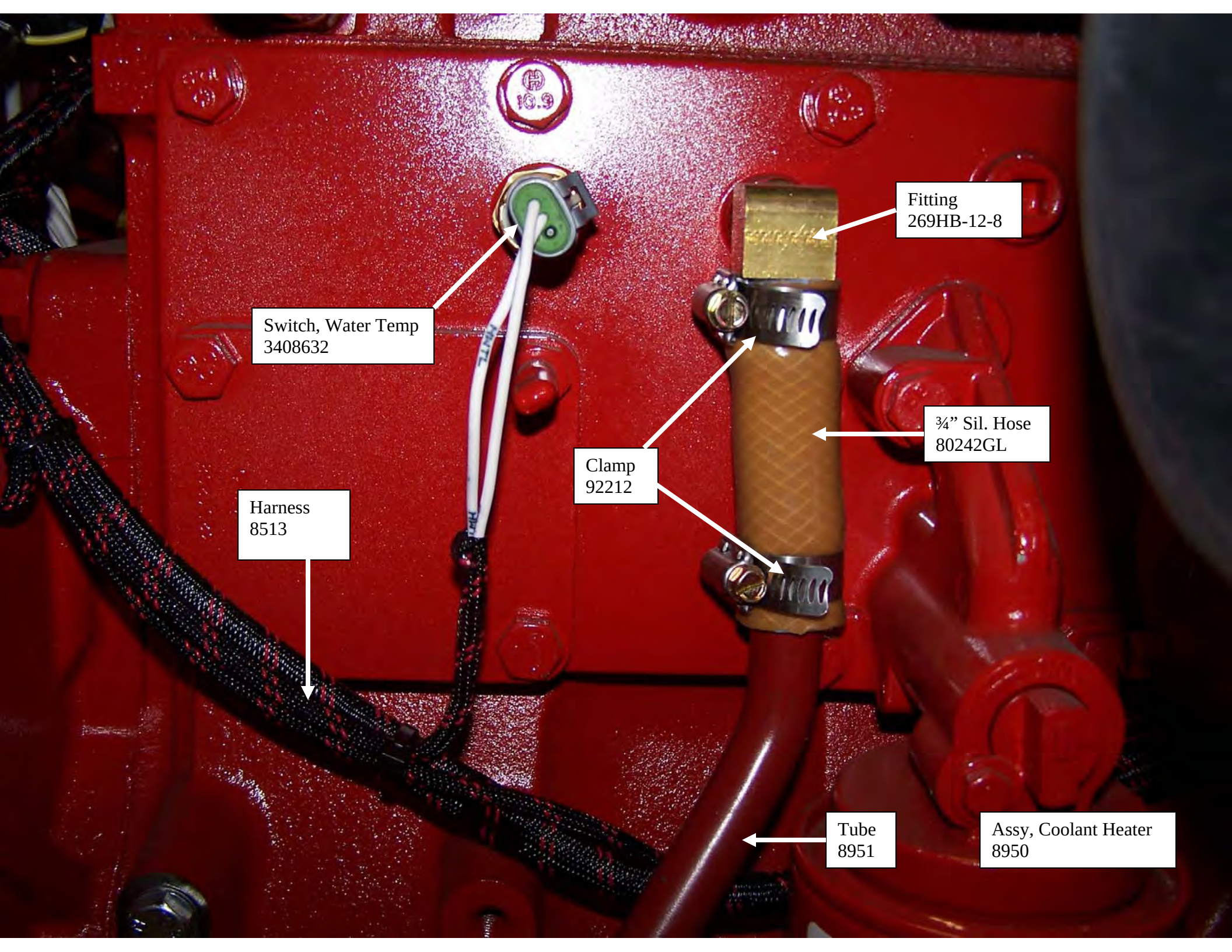

Switch, Water Temp
3408632

Harness
8513


Clamp
92212

Fitting
269HB-12-8

3/4" Sil. Hose
80242GL

Tube
8951

Assy, Coolant Heater
8950

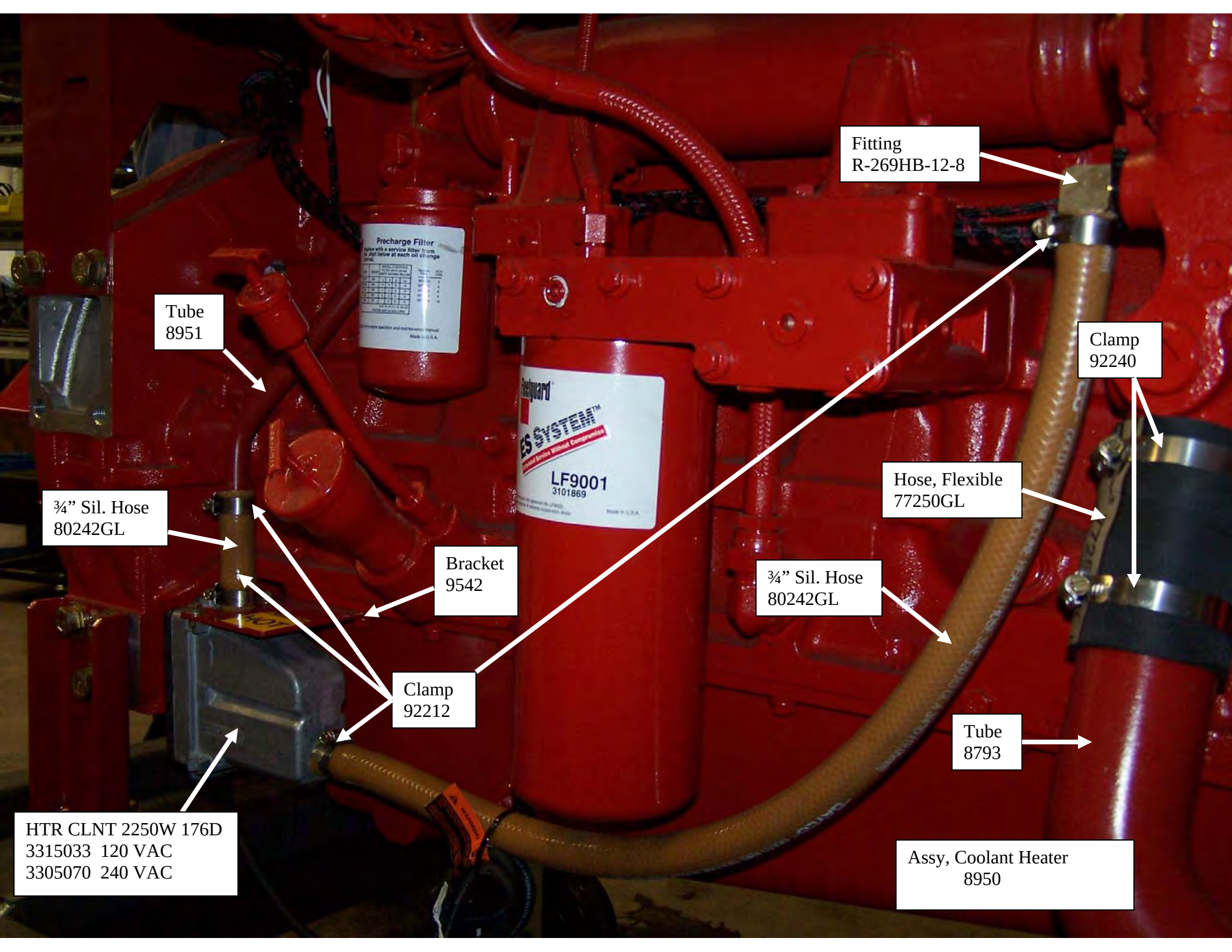

Tube
8951

¾" Sil. Hose
80242GL

Bracket
9542

Clamp
92212

Fitting
R-269HB-12-8

Hose, Flexible
77250GL


¾" Sil. Hose
80242GL

Clamp
92240

Tube
8793

HTR CLNT 2250W 176D
3315033 120 VAC
3305070 240 VAC

Assy, Coolant Heater
8950

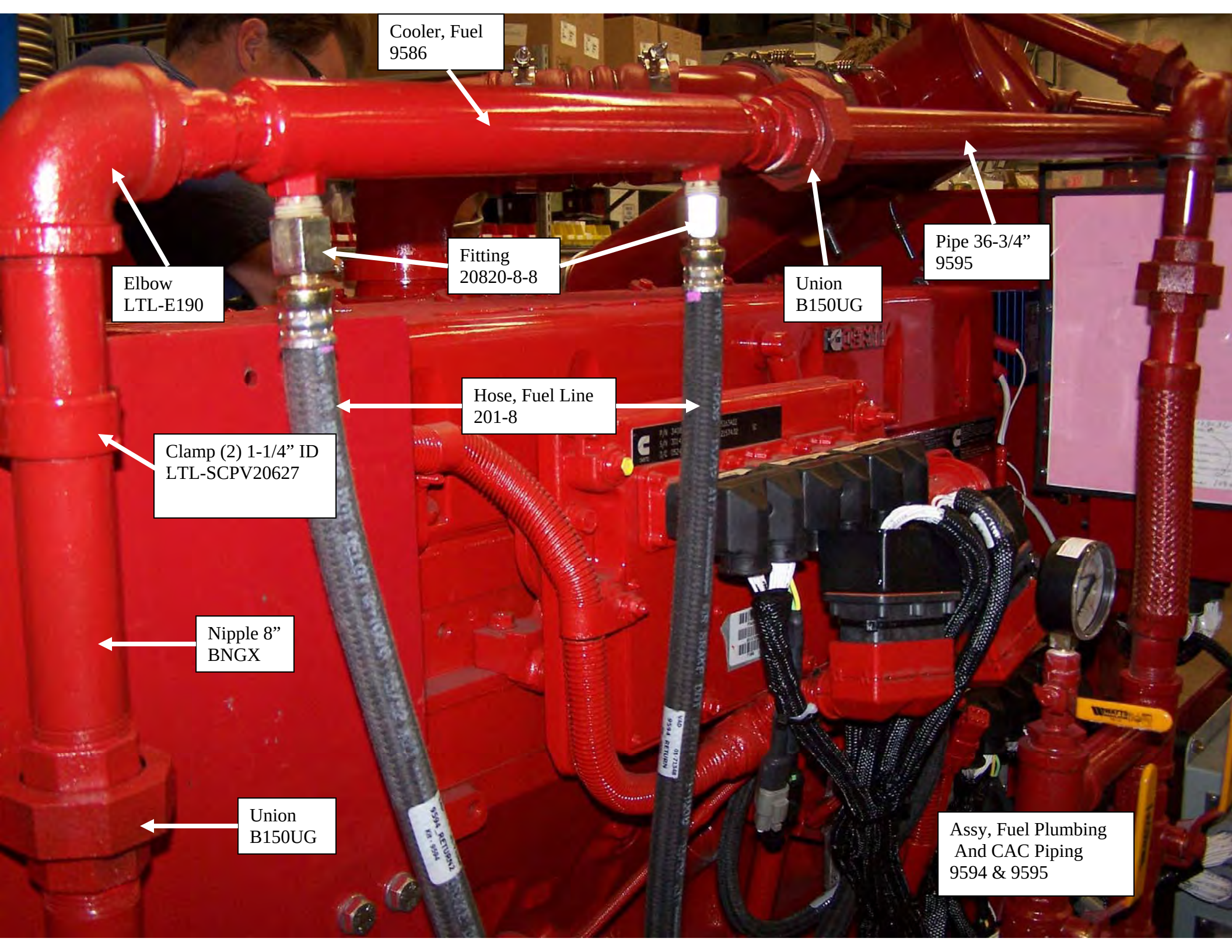

Cooler, Fuel
9586

Elbow
LTL-E190

Fitting
20820-8-8

Union
B150UG

Pipe 36-3/4"
9595


Hose, Fuel Line
201-8

Clamp (2) 1-1/4" ID
LTL-SCPV20627

Nipple 8"
BNGX

Union
B150UG

Assy, Fuel Plumbing
And CAC Piping
9594 & 9595

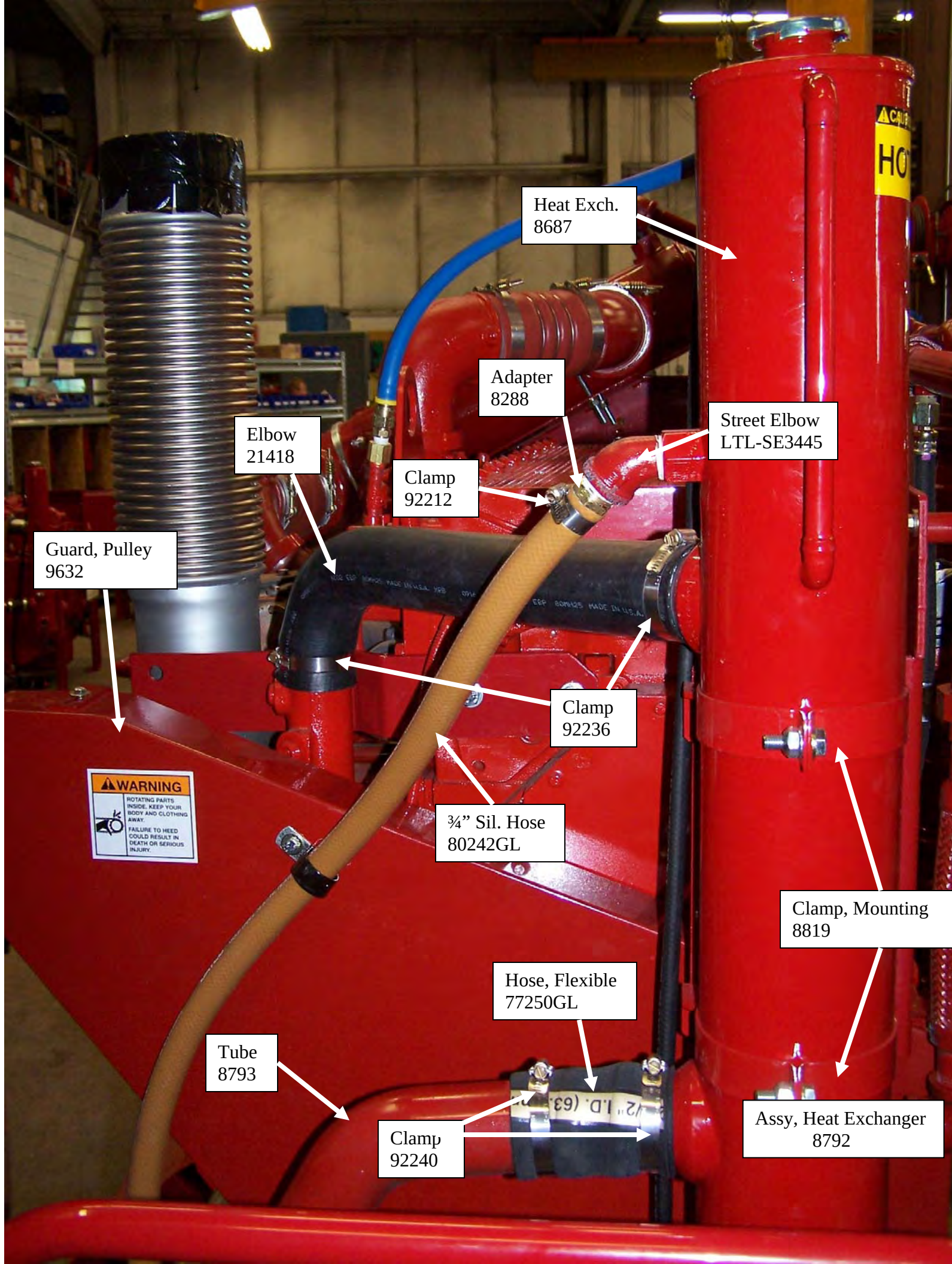

Heat Exch.
8687

Adapter
8288

Street Elbow
LTL-SE3445

Elbow
21418

Clamp
92212

Guard, Pulley
9632

Clamp
92236

3/4" Sil. Hose
80242GL

Clamp, Mounting
8819


Hose, Flexible
77250GL

Tube
8793

Clamp
92240

Assy, Heat Exchanger
8792

WARNING
ROTATING PARTS
INSIDE. KEEP YOUR
BODY AND CLOTHING
AWAY.
FAILURE TO HEED
COULD RESULT IN
DEATH OR SERIOUS
INJURY.

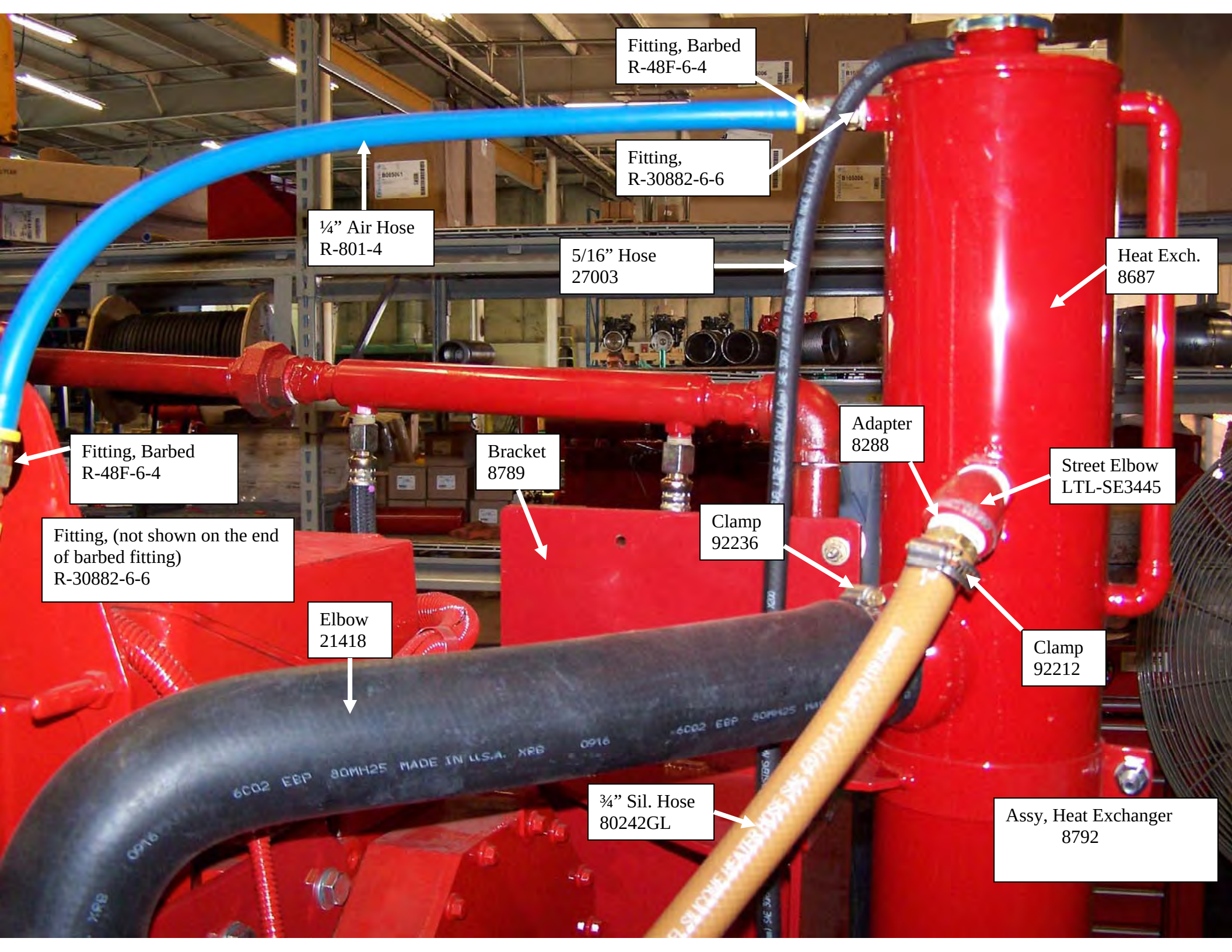

Fitting, Barbed
R-48F-6-4

Fitting,
R-30882-6-6

1/4" Air Hose
R-801-4

5/16" Hose
27003

Heat Exch.
8687

Fitting, Barbed
R-48F-6-4

Fitting, (not shown on the end
of barbed fitting)
R-30882-6-6

Bracket
8789

Adapter
8288

Street Elbow
LTL-SE3445


Clamp
92236

Elbow
21418

Clamp
92212

3/4" Sil. Hose
80242GL

Assy, Heat Exchanger
8792

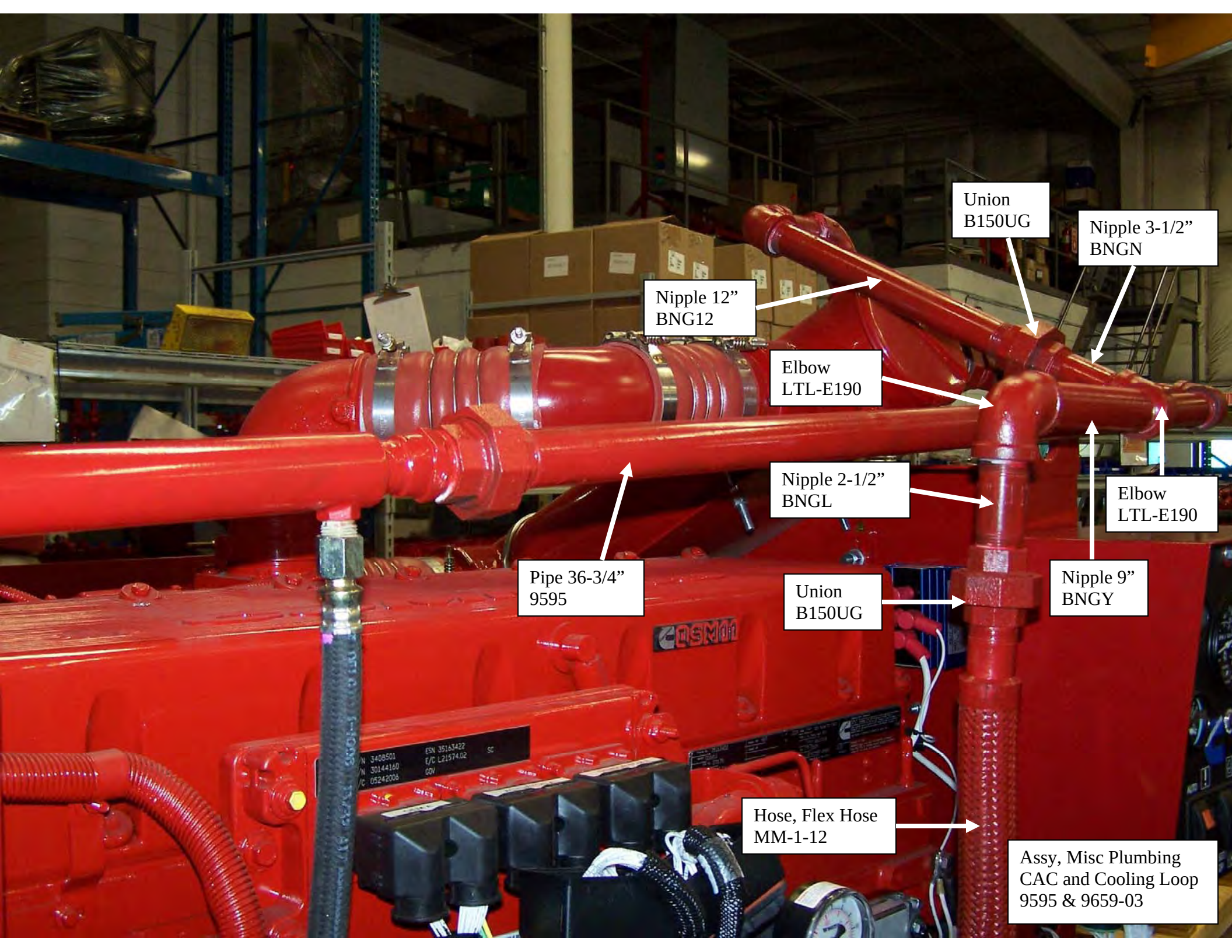

Nipple 12"
BNG12

Elbow
LTL-E190

Union
B150UG

Nipple 3-1/2"
BNGN

Nipple 2-1/2"
BNGL

Elbow
LTL-E190


Pipe 36-3/4"
9595

Union
B150UG

Nipple 9"
BNGY

Hose, Flex Hose
MM-1-12

Assy, Misc Plumbing
CAC and Cooling Loop
9595 & 9659-03

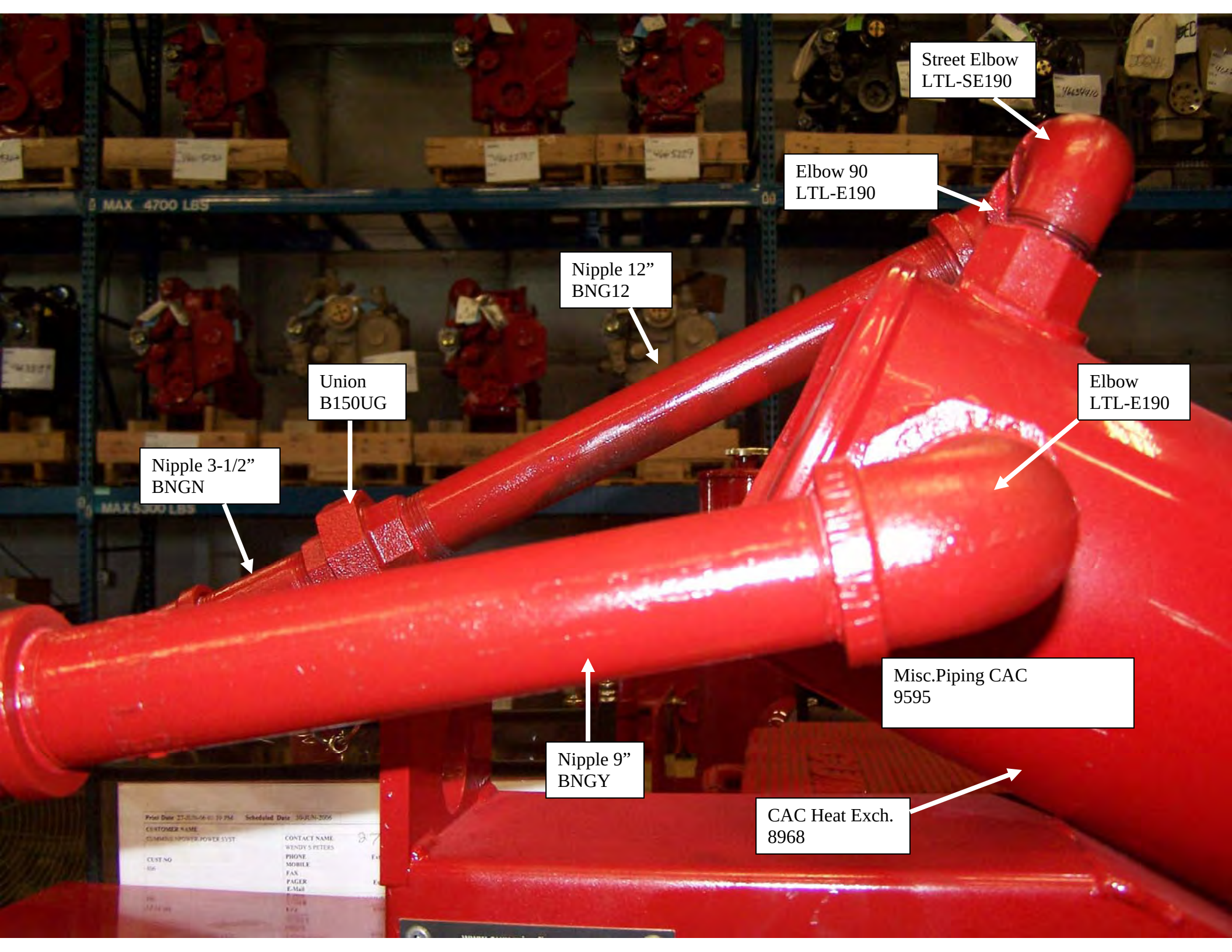

Street Elbow
LTL-SE190

Elbow 90
LTL-E190

Nipple 12"
BNG12

Union
B150UG

Nipple 3-1/2"
BNGN


Elbow
LTL-E190

Misc.Piping CAC
9595

Nipple 9"
BNGY

CAC Heat Exch.
8968

Print Date: 27-JUN-2006 10:29 PM Scheduled Date: 30-JUN-2006	
CUSTOMER NAME	
CONDENSER POWER POWER SYST	
CUST NO	CONTACT NAME
106	WENDY S PETERS
	PHONE
	MOBILE
	FAX
	PAGER
	E-Mail
	FAX
	FAX
	FAX

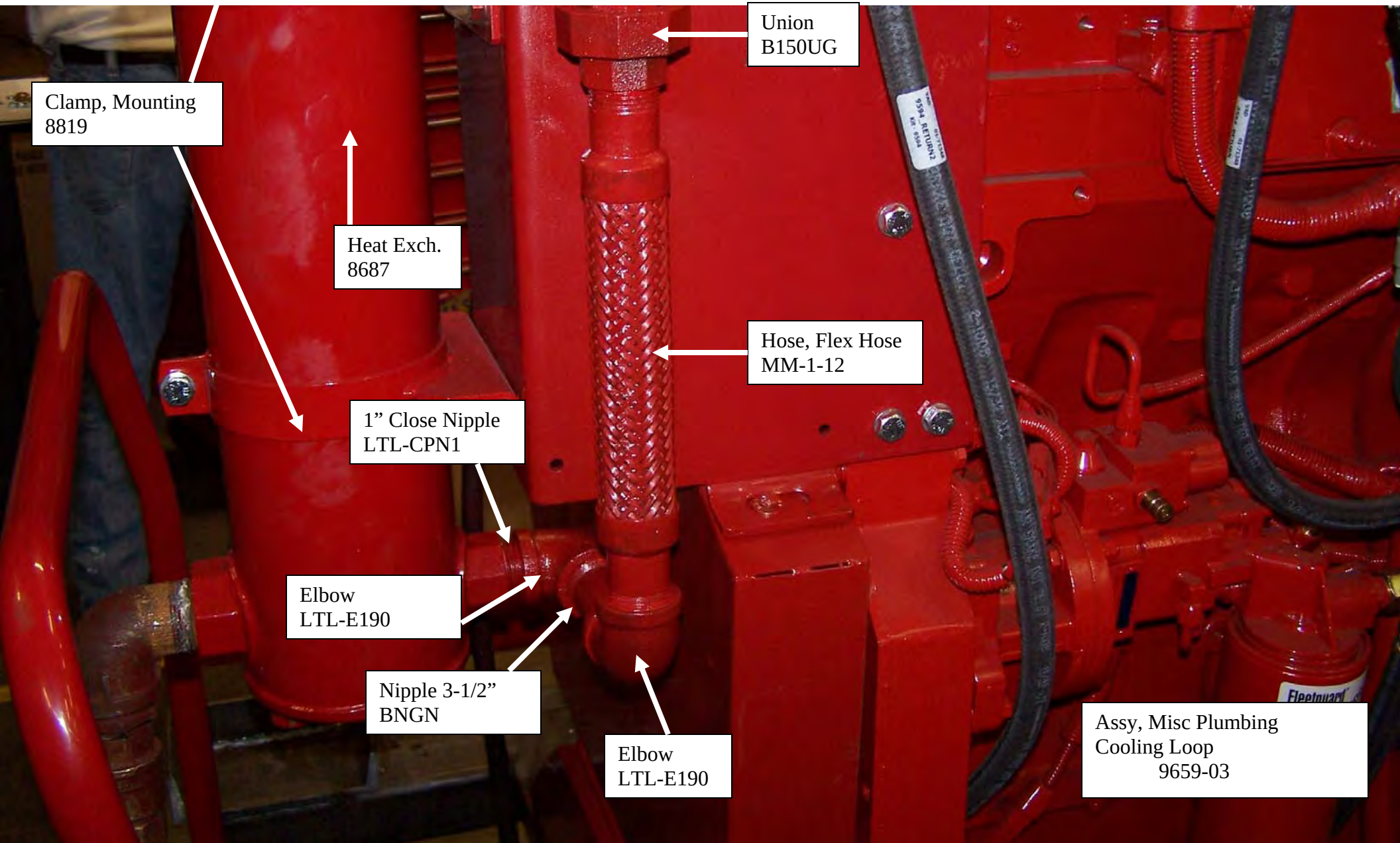

Clamp, Mounting
8819

Heat Exch.
8687

Union
B150UG

Hose, Flex Hose
MM-1-12


1" Close Nipple
LTL-CPN1

Elbow
LTL-E190

Nipple 3-1/2"
BNGN

Elbow
LTL-E190

Assy, Misc Plumbing
Cooling Loop
9659-03

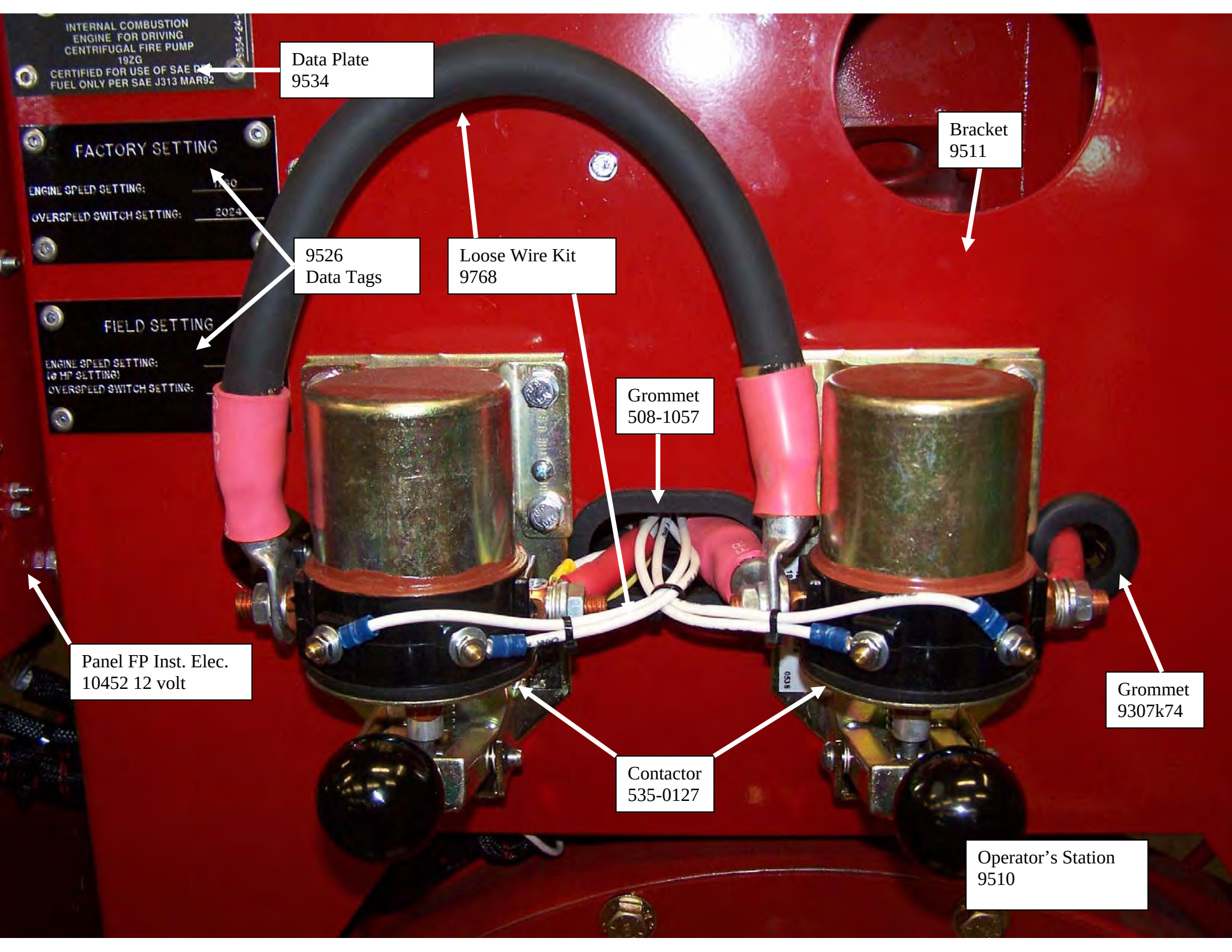

INTERNAL COMBUSTION
ENGINE FOR DRIVING
CENTRIFUGAL FIRE PUMP
192G
CERTIFIED FOR USE OF SAE D
FUEL ONLY PER SAE J313 MAR92

Data Plate
9534

FACTORY SETTING

ENGINE SPEED SETTING: _____

OVERSPEED SWITCH SETTING: _____

9526
Data Tags

Loose Wire Kit
9768

Bracket
9511

FIELD SETTING

ENGINE SPEED SETTING: _____

(@ HP SETTING)
OVERSPEED SWITCH SETTING: _____

Grommet
508-1057

Panel FP Inst. Elec.
10452 12 volt

Grommet
9307k74

Contactor
535-0127

Operator's Station
9510


Wiring Harness
8513


Isolator, Vibration
51156PS

Bracket
9597

Wiring Harness
9533

ECM Secondary
9596 2 of 2

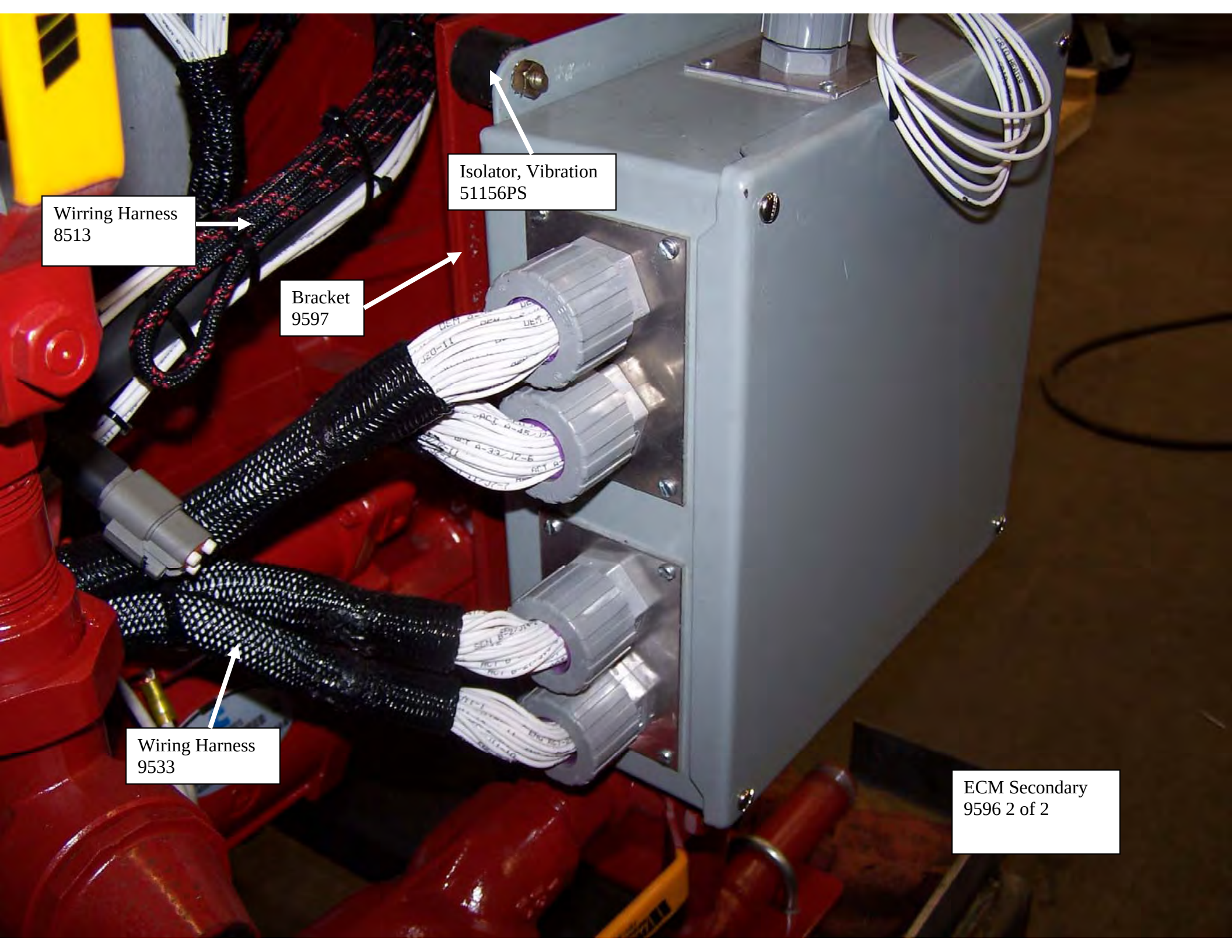

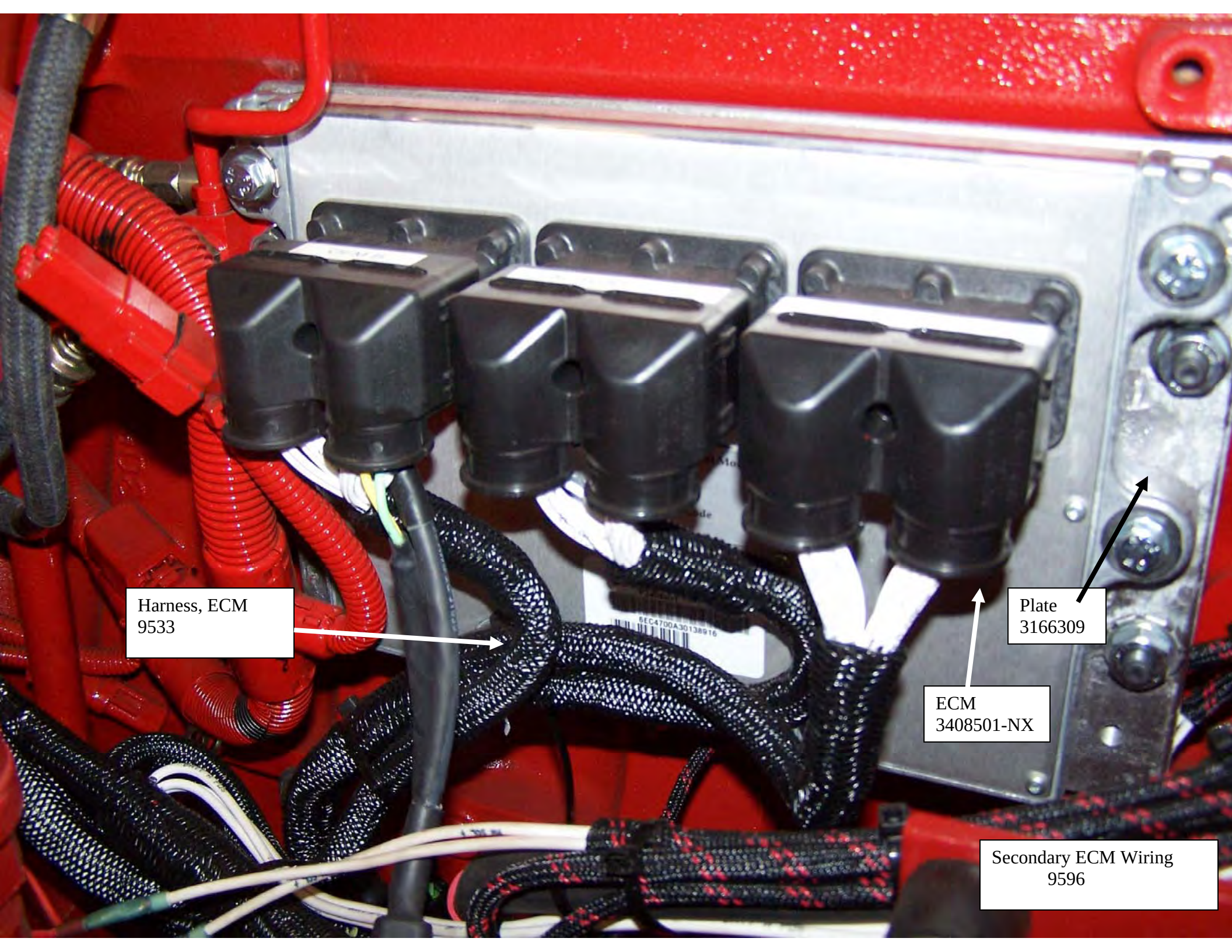
A close-up photograph of an engine's electrical system. Three black plastic connectors are mounted on a silver metal plate. Red corrugated hoses and black braided wires are visible. A white label with a barcode is attached to the middle connector. Arrows point from text labels to specific components: 'Harness, ECM 9533' points to a bundle of black wires, 'ECM 3408501-NX' points to the middle connector, 'Plate 3166309' points to the metal plate, and 'Secondary ECM Wiring 9596' points to a bundle of black and red wires at the bottom.

Harness, ECM
9533

ECM
3408501-NX

Plate
3166309

Secondary ECM Wiring
9596

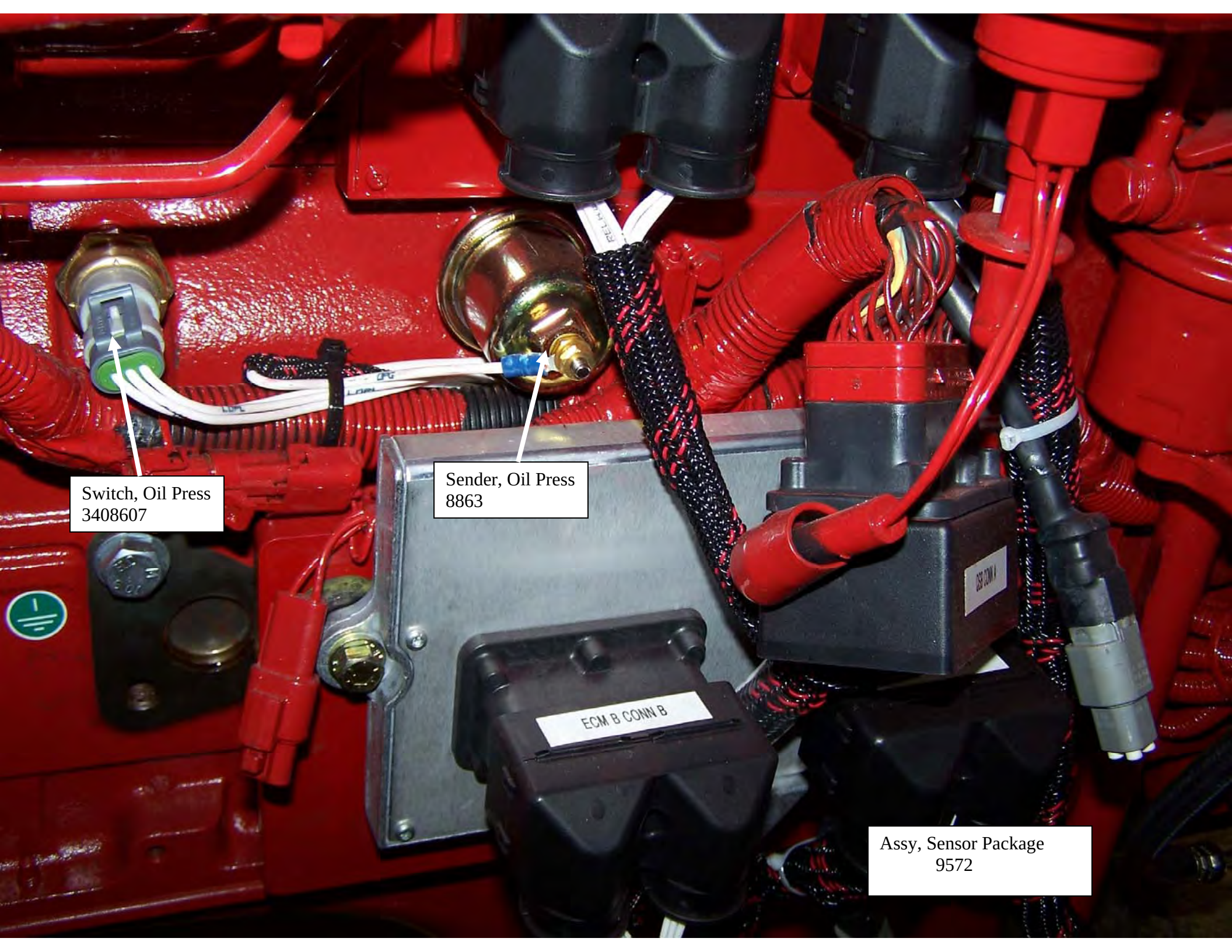

Switch, Oil Press
3408607

Sender, Oil Press
8863

Assy, Sensor Package
9572

ECM B CONN B

Bulkhead
8-WGTX-WLNS

Fuel Line Ext and plug
10233
LTL- SCSP12 (not
shown)

Bulkhead
10-WGTX-WLNS

Fuel Line Ext and plug
10234
LTL- SCSP38 (not
shown)

Assy, Fuel Plumbing
9594

