

PORTABLE POWER

Cummins rechargeable battery
Power Stations, gas-powered
inverters and dual fuel generators



**FOR
A WORLD
THAT'S
ALWAYS ON™**

POWER THAT'S SUSTAINABLE

Onan Power Stations



ENVIRONMENTALLY FRIENDLY

Rechargeable batteries provide the electricity, not internal combustion engines



DURABLE

Solid construction is built to last



LIGHTWEIGHT

Easy to transport wherever you need power



WHISPER QUIET

No internal combustion engine means they are nearly silent



LOW MAINTENANCE

No regular oil and filter changes are needed



A VARIETY OF SIZES

Available in 160, 200, 300, 600 and 1,000 watts

ONAN PS160

160-Watt Rechargeable Power Station
155 Watt-Hours | 100 Running Watts
| 150 Peak Watts

- Dimensions: 8" L x 3.5" W x 7" H
- Weight: 3.75 lbs
- Battery type: Lithium-Ion
- Charge time: 4 hours (AC/DC)
- AC Outlets: 2 x 120 V standard household outlets
- DC Outlets: 2 x USB-A, 1 x USB QC 3.0, 1 USB-C and 3 x 5.5 mm 9-12 V
- Light with SOS mode: No
- Charging port: 5.5 mm
- Overload protection: yes
- Warranty: 2 years or 500 cycles

ONAN PS200

200-Watt Rechargeable Power Station
194 Watt-Hours | 150 Running Watts
| 300 Peak Watts

- Dimensions: 8" L x 3.5" W x 7.5" H
- Weight: 4 lbs
- Battery type: Lithium-Ion
- Charge time: 4 hours (AC/DC)
- AC Outlets: 2 x 120 V standard household outlets
- DC Outlets: 1 x USB-A, 1 x USB QC 3.0, 1 USB-C and 1 x 6 mm 9-12 V
- Light with SOS mode: Yes
- Charging port: 8 mm
- Overload protection: yes
- Warranty: 2 years or 500 cycles



ONAN PS300

300-Watt Rechargeable Power Station
296 Watt-Hours | 300 Running Watts
| 600 Peak Watts

- Dimensions: 9" L x 5" W x 9" H
- Weight: 6.5 lbs
- Battery type: Lithium-Ion
- Charge time: 5 hours (AC/DC)
- AC Outlets: 2 x 120 V standard household outlets
- DC Outlets: 1 x USB-A, 1 x USB QC 3.0, 1 USB-C, 1 x 6 mm 9-12 V and 1 x 12 V 8 A car cigarette lighter outlet
- Light with SOS mode: Yes
- Charging port: 8 mm
- Overload protection: yes
- Warranty: 2 years or 500 cycles

ONAN PS600

600-Watt Rechargeable Power Station
592 Watt-Hours | 600 Running Watts
| 1,200 Peak Watts

- Dimensions: 11.5" L x 6.5" W x 11.5" H
- Weight: 11 lbs
- Battery type: Lithium-Ion
- Charge time: 7-8 hours (AC/DC)
- AC Outlets: 2 x 120 V standard household outlets
- DC Outlets: 1 x USB-A, 2 x USB QC 3.0, 1 USB-C, 1 x 6 mm 9-12 V and 1 x 12 V 8 A car cigarette lighter outlet
- Light with SOS mode: Yes
- Charging port: 8 mm
- Overload protection: yes
- Warranty: 2 years or 500 cycles

ONAN PS1000

1,000-Watt Rechargeable Power Station
1,008 Watt-Hours | 1,500 Running Watts
| 3,000 Peak Watts

- Dimensions: 12.4" L x 8" W x 12.3" H
- Weight: 31 lbs
- Battery type: Lithium-Ion
- Charge time: 2 hours (AC/DC)
- AC Outlets: 6 x 120 V standard household outlets
- DC Outlets: 2 x USB-A, 2 x USB QC 3.0, 2 USB-C, 1 x 12 V 8 A car cigarette lighter outlet
- Light with SOS mode: Yes
- Charging port: XT-60
- Overload protection: yes
- Warranty: 2 years or 500 cycles

POWER WHEN YOU NEED IT MOST

Onan Portable Generators



POWER YOUR
ADVENTURES

ONAN P2500i

2,500-Watt Digital Inverter Gasoline Portable Generator
2,200 Running Watts | 2,500 Peak Watts



DIGITAL INVERTER GENERATOR

Efficient, clean energy that requires little maintenance



PARALLEL CAPABLE

Parallels with another P2500i inverter generator



QUIET & DURABLE

Double-insulated



LIGHTWEIGHT

Easy to carry



KEEPS YOU CONNECTED

Low THD for clean power – perfect for sensitive electronics



FUEL EFFICIENT

1-gallon fuel tank that runs 10 hrs at 25% load

- Dimensions 19.75" L x 10.5" W x 18.25" H
- Dry weight 48 lbs
- Parallel capable with another P2500i inverter generator
- Two 5V USB ports for charging sensitive electronics, such as phones or tablets
- Dependable 98cc Cummins Onan OHV 4-Stroke engine
- Built-in carry handle for easy transportation
- Rubber outlet dust covers
- Rubber mat on top for storing electronic devices, such as phones, while charging
- 3-year warranty



POWER YOUR
ADVENTURES

ONAN P4500i

4,500-Watt Digital Inverter Gasoline Portable Generator
3,700 Running Watts | 4,500 Peak Watts



DIGITAL INVERTER GENERATOR

Efficient, clean energy that requires little maintenance



PUSH BUTTON & REMOTE START

Pull cord backup



QUIET & DURABLE

Double insulated



PARALLEL CAPABLE

Parallels with another P4500i inverter generator



FUEL EFFICIENT

3.4-gallon fuel tank that runs 18 hrs at 25% load



LIGHTWEIGHT

At 98 pounds, and with a telescopic handle and built-in wheels, it's lighter and easier to manage

- Dimensions 24.5" L x 18.25" W x 20.5" H
- Dry weight 98 lbs
- RV- and camper-ready with 30 A TT-30R outlet
- Parallel capable with another P4500 inverter generator to reach 50 A of power
- Two 5 V USB ports for charging sensitive electronics, such as phones or tablets
- Dependable 224cc Cummins Onan OHV 4-Stroke engine
- Rubber outlet dust covers
- Telescoping handle for easy transportation
- 3-year warranty



POWER YOUR
WORLD

ONAN P4500IDF

4,500-Watt Dual Fuel Digital Inverter Portable Generator
Gas: 3,700 Running Watts | 4,500 Peak Watts
Propane: 3,330 Running Watts | 4,050 Peak Watts



DIGITAL INVERTER GENERATOR

Efficient, clean energy that requires little maintenance



PUSH BUTTON & REMOTE START

Pull cord backup



DUAL FUEL CAPABLE

Easily switch from gas to propane with a fuel capacity of 3.4 gallons



QUIET & DURABLE

Double-insulated



PARALLEL CAPABLE

Parallels with another P4500 inverter generator



LIGHTWEIGHT

107.4 pounds, telescopic handle and built-in wheels make it easy to manage

- Dimensions 25.5" L x 18.12" W x 20.5" H
- Dry weight 104.7 lbs
- RV- and camper-ready with 30 A TT-30R outlet
- Parallel capable with another P4500 inverter generator to reach 50 A of power
- Two 5 V USB ports for charging sensitive electronics such as phones or tablets
- Dependable 224cc Cummins Onan OHV 4-Stroke engine
- Rubber outlet dust covers
- Telescoping handle for easy transportation
- 3-year warranty



POWER WHEN
YOU NEED IT MOST

ONAN P9500DF

9,500-Watt Dual Fuel (Gas/LPG) Portable Generator
Gas: 7,500 Running Watts | 9,500 Peak Watts
Propane: 6,750 Running Watts | 8,550 Peak Watts



PUSH BUTTON & REMOTE START

Pull cord backup



DUAL FUEL CAPABLE

Easily switch from gas to propane with a fuel capacity of 6.6 gallons



ESSENTIAL DATA DISPLAY


VFT Data Center displays volts, frequency, run time, maintenance reminders and lifetime hours

- Dimensions 27.25" L x 26.25" W x 26.25" H
- Dry weight 194 lbs
- Easily change fuel source from gasoline to propane
- Dependable 420cc Cummins Onan OHV 4-Stroke engine
- Fuel gauge on top of 6.6-gallon tank
- Battery charging port with charger included
- Rubber outlet dust covers
- Wheel kit included
- 3-year warranty


LED DISPLAYS*

Precise readings to keep you in the know.

Generators

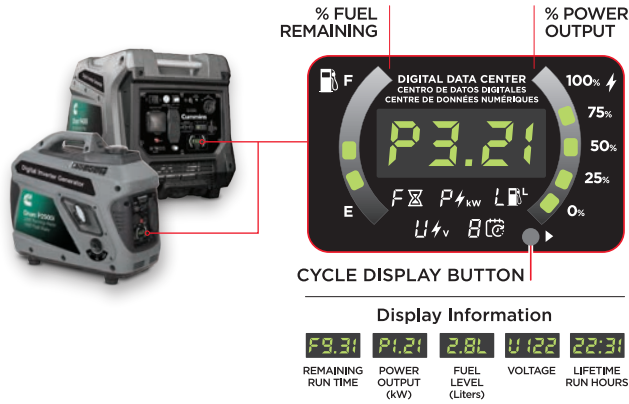

Power Stations

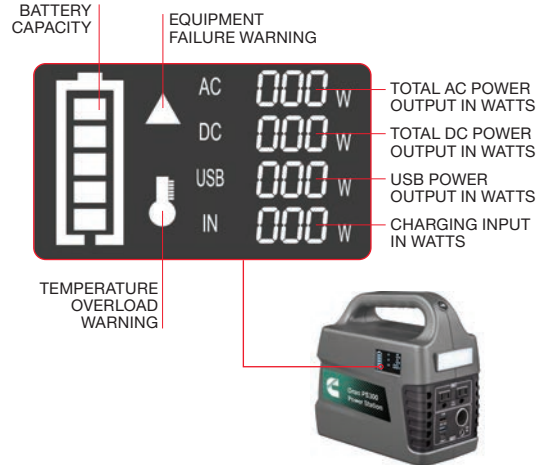

*Displays shown are for illustration purposes only. Displays vary depending on model.





Cummins Inc.
Box 3005
Columbus, IN 47202-3005
U.S.A.

cummins.com

Bulletin 5300167 Produced in U.S.A. Rev. 2/23
©2023 Cummins Inc.