

# STILL IN THE NIGHT

Onan RV Generators  
QG 2800i / 2500i Models



100 YEARS OF  
**POWER**  
GENERATION

# THE REST OF THE WORLD WON'T KNOW YOU'RE THERE.



## Variable-speed PMA generator

- 63% less noise
- 61% less vibration
- Slows the engine down to improve fuel efficiency at moderate operating loads

## Electronic fuel ignition

- No carburetor varnishing, no yearly maintenance, automatic altitude adjustment

## 40% larger oil capacity

- Greater cooling capacity

## Three-point isolation mounts and integrated muffler flex coupling

- Reduce vibrations felt inside of RV

## Oil and inverter temperature sensors

- Shut down generator to protect equipment if oil or inverter exceed recommended range

## Oil level and pressure monitoring

- No daily oil check necessary

## Available in gas or LP (propane) models

- Provides fuel flexibility and can eliminate the need for alternative fuel tanks
- EVAP model available for towable applications

## 9% lighter than previous model

- Increases cargo capacity

## Inverter control

- Prevents nuisance circuit breaker tripping
- J1939 communication system expands generator operation and monitoring generator functions on OEM status display panels

# SPECIFICATIONS

REDESIGNED AND IMPROVED ONAN QG 2800i / 2500i	
<b>Sound</b>	64.1 dBA at no load 64.6 dBA at half load
<b>Speed</b>	Variable
<b>Alternator</b>	PMA alternator
<b>Power delivery</b>	Voltage regulation +/- 1% Frequency regulation +/- 1.5%
<b>Spark arrestor</b>	No maintenance
<b>Ignition</b>	Return-less, computer-controlled electronic fuel injection
<b>Controls</b>	J1939 interface and remote controls
<b>Oil capacity</b>	1 qt
<b>Fuel consumption</b>	Gasoline: 0.4 gal/hour at half load LP: 1.3 lbs/hour (0.3 gal/hour at half load)
<b>EVAP</b>	Available
<b>Weight</b>	113 lbs/51.2 kg
<b>Size</b>	Length: 22 in/560 mm Width: 16.9 in/430 mm Height: 13.4 in/340 mm

## REDESIGNED TO PROVIDE:



**HIGHER  
EFFICIENCY**



**LOWER NOISE  
LEVELS**



**LOWER VIBRATION  
LEVELS**



**PURE SINE  
POWER**


For more information about Cummins RV generators, contact your local RV dealer or visit [cummins.tech/qg2800i](http://cummins.tech/qg2800i)



# ANYWHERE YOU WANT TO GO

Cummins offers unrivaled peace of mind when it comes to servicing and maintaining your Onan RV generator. You will be supported by authorized service centers across the United States.

The map below shows the number of dealers in each state. Find one near you: [locator.cummins.com](http://locator.cummins.com)

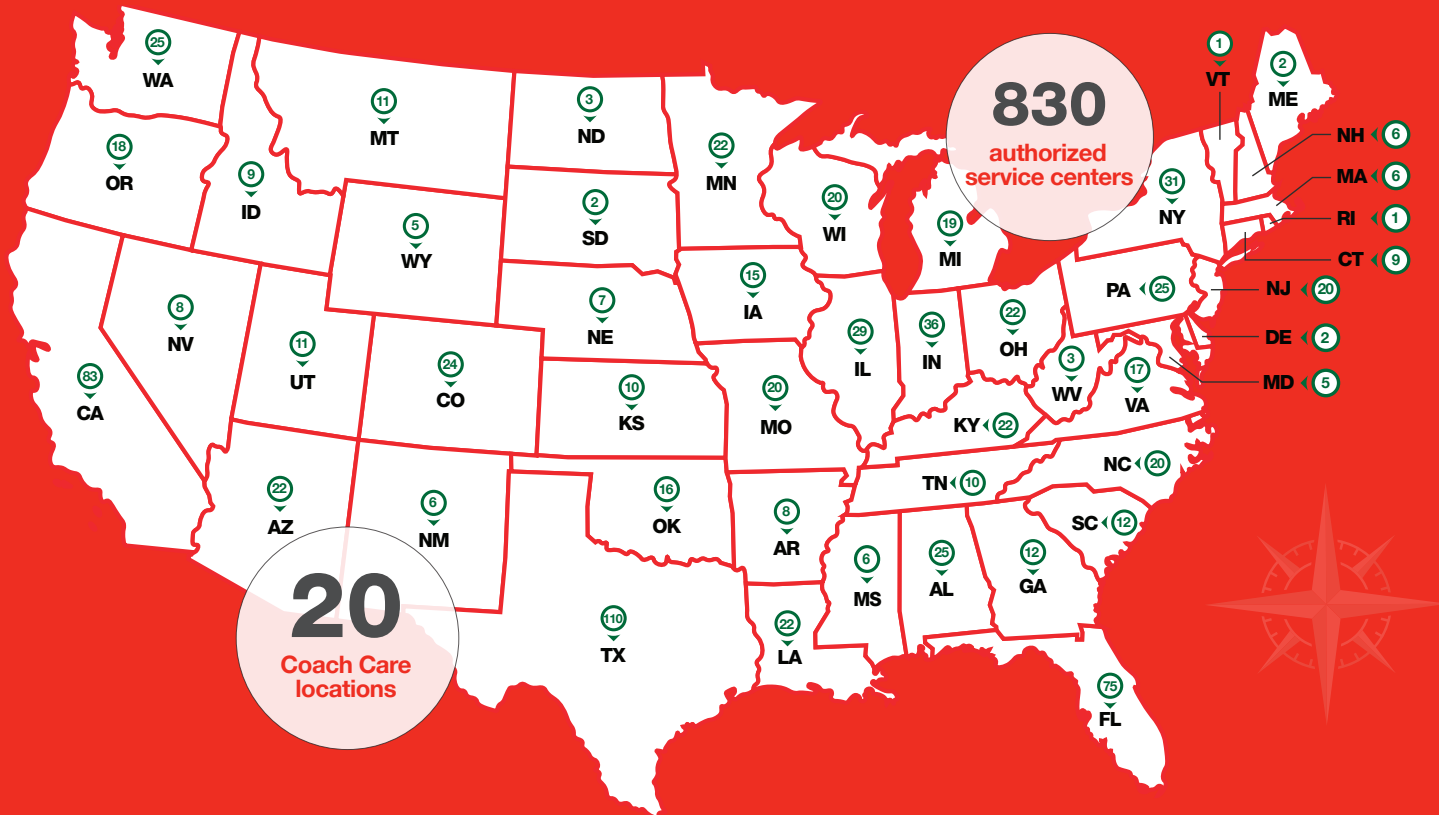

## LEADING SERVICE AND SUPPORT

Your Onan RV generator is supported by the largest service network with more than 1,000 authorized Cummins RV dealers and over 150 Cummins distributors.

Genuine Cummins Green Label Parts™ and maintenance products have been designed and tested for the Onan QG 2800i / 2500i models to provide dependable power and performance for the life of your Onan RV generator.

Cummins offers a blend of OnaMax™ oil, SAE 10W-30 (part number A063E183) as the recommended weight for the HGLAA as well as all gasoline and LP generators. Learn more at [cummins.tech/SAE10W-30](http://cummins.tech/SAE10W-30).

You can find the SAE 10W-30 OnaMax oil blend as well as all other Genuine Cummins Green Label Parts at any Cummins distributor or authorized Cummins RV dealer.



Cummins Inc.  
Box 3005  
Columbus, IN 47202-3005  
U.S.A.

1-800-CUMMINS™ (1-800-286-6467)  
cummins.com

Bulletin 5676435 Produced in U.S.A. 2/21  
©2021 Cummins Inc.